

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190370010](#)
Status: **Active**
Overview: Standard Quick-Disconnect Terminals
Description: Krimptite™ Female Bullet Receptacle for 18-22 AWG Wire, 3.96mm Diameter, Open Barrel, Metal Strip Carrier

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)

General

Product Family	Quick Disconnects
Series	19037
Comments	Fits Male Plug Dia. 3.96mm
Crimp Quality Equipment	Yes
Insulated	No
Overview	Standard Quick-Disconnect Terminals
Product Name	Krimptite™
Type	Snap Receptacle
UPC	800755059052

Physical

Barrel Type	Open
Gender	Female
Glow-Wire Compliant	No
Insulation	None
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.566/g
Orientation	Straight
Packaging Type	Reel
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Tab Thickness	N/A
Tab Width	N/A
Temperature Range - Operating	Per Wire Specification
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	N/A
Wire Size AWG	18, 20, 22
Wire Size mm²	0.25 - 1.50

Electrical


Voltage - Maximum	Per Wire Specification
-------------------	------------------------

Material Info

Old Part Number	AAZ-1125
-----------------	----------

Reference - Drawing Numbers

Product Specification	PS-19902-011
Sales Drawing	SD-19037-001

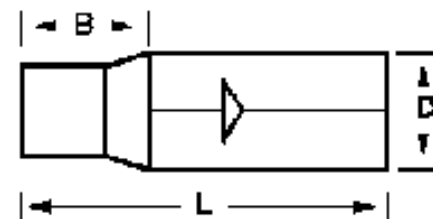

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Contains SVHC(2014 December 17): No

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Relevant

ELV

Not Relevant

Search Parts in this Series

[19037 Series](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Hand Crimp Tool	0640031100
ASP Perishable Tool Kit used in ASP presses that process metal strip product	0190290091
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640071100
Mini-Mac™ Applicator	0638815800

This document was generated on 06/23/2015

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19037-0010](#)