

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0190472030](#)  
**Status:** **Active**  
**Overview:** [Application Tooling](#)  
**Description:** Crimp Dies for 8 AWG InsulKrimp and NylaKrimp Mylar Tape, use with the 640162000 Tape Crimp Module and 638017600 TM-4000 Crimp Press

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**General**


Product Family	Application Tooling
Series	<a href="#">207126</a>
Comments	ATP Tooling Kit Used with Molex Crimp Tape Module; 640162000 in a Molex TM-4000 press; 638017600, and in the ATP-201 Air Tape Press; 190470001, See Tooling Specification (PDF) Above for more details.
Function	Crimp
Geographic Area	Global
Level of Automation	Semi-Automatic
More Detailed Tech Information	<a href="mailto:applicationtooling@molex.com">applicationtooling@molex.com</a>
Overview	<a href="#">Application Tooling</a>
Product Name	ETC
Tool Type	Crimp Module
UPC	800753052666
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

**Material Info**

**Reference - Drawing Numbers**

Application Tooling Documents

ATS-190472030-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

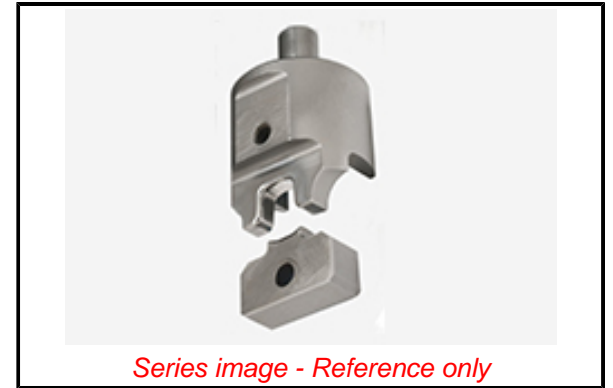

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[207126 Series](#)

**Use With**

Molex ATP-201 Air Crimp Press [190470001](#);  
Molex TM-4000 Crimp Press [638017600](#)  
with Tape Crimp Module [640162000](#)

**Application Tooling**

**FAQ**

**Description**

**Product #**

NylaKrimp Funnel [190670038](#)

Entry Ring Tongue Terminal for 8 AWG Wire, Stud Size 8 (M4), Adhesive Tape on Reel

InsulKrimp Ring [190710139](#)

Tongue Terminal for 8 AWG Wire, Stud Size 10 (M5), Length 33.17mm, Mylar Tape Carrier

InsulKrimp Ring [190710149](#)

Tongue Terminal for 8 AWG Wire, Stud Size 1/4" (M6),

Length 36.25mm,  
Mylar Tape Carrier  
InsulKrimp Ring 190710152  
Tongue Terminal  
for 8 AWG Wire,  
Stud Size 3/8" (M9),  
Length 36.25mm,  
Mylar Tape Carrier  
InsulKrimp Ring 190710155  
Tongue Terminal  
for 8 AWG Wire,  
Stud Size 5/16" (M8),  
Length 36.25mm,  
Mylar Tape Carrier  
InsulKrimp Ring 190710177  
Tongue Terminal for  
8 AWG Wire, Stud  
Size 6 (M3.5), Mylar  
Tape Carrier  
InsulKrimp Ring 190710179  
Tongue Terminal for  
8 AWG Wire, Stud  
Size 8 (M4), Mylar  
Tape Carrier  
InsulKrimp Ring 190710181  
Tongue Terminal for  
8 AWG Wire, Stud  
Size 10 (M5), Mylar  
Tape Carrier  
InsulKrimp Ring 190710184  
Tongue Terminal for  
8 AWG Wire, Stud  
Size 1/4" (M6), Mylar  
Tape Carrier

This document was generated on 07/28/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19047-2030](#)