

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190472040](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: Crimp Dies for 6 AWG InsulKrimp and NylaKrimp Mylar Tape, use with the 640162000 Tape Crimp Module and 638017600 TM-4000 Crimp Press

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Application Tooling
Series	207126
Comments	ATP Tooling Kit Used with Molex Crimp Tape Module; 640162000 in a Molex TM-4000 press; 638017600, and in the ATP-201 Air Tape Press; 190470001, See Tooling Specification (PDF) Above for more details.
Function	Crimp
Geographic Area	Global
Level of Automation	Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	ETC
Tool Type	Crimp Module
UPC	800753052680
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers

Application Tooling Documents

ATS-190472040-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

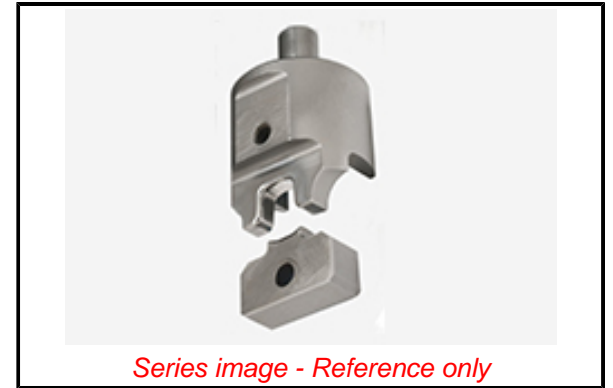

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[207126 Series](#)

Use With

Molex ATP-201 Air Crimp Press [190470001](#);
Molex TM-4000 Crimp Press [638017600](#)
with Tape Crimp Module [640162000](#)

Application Tooling | [FAQ](#)

Description | **Product #**

NylaKrimp Funnel Entry Ring Tongue Terminal for 6 AWG Wire, Stud Size 1/4" (M6)	190670072
InsulKrimp Brazed Ring Tongue Terminal for 6 AWG Wire, Expanded Flare, Stud Size 10 (M5), Length 42.34mm, Mylar Tape Carrier	190710189
InsulKrimp Brazed Ring Tongue Terminal for 6 AWG Wire, Expanded	190710192

Flare, Stud Size
1/4" (M6), Length
42.34mm, Mylar
Tape Carrier
InsulKrimp Brazed [190710195](#)
Ring Tongue
Terminal for 6 AWG
Wire, Expanded
Flare, Stud Size
3/8" (M9), Length
42.34mm, Mylar
Tape Carrier
InsulKrimp Brazed [190710198](#)
Ring Tongue
Terminal for 6 AWG
Wire, Expanded
Flare, Stud Size
5/16" (M8), Length
42.34mm, Mylar
Tape Carrier
InsulKrimp Brazed [190710219](#)
Ring Tongue
Terminal for 6 AWG
Wire, Expanded
Flare, Stud Size
8 (M4), Length
40.54mm, Mylar
Tape Carrier
InsulKrimp Brazed [190710223](#)
Ring Tongue
Terminal for 6 AWG
Wire, Expanded
Flare, Stud Size
10 (M5), Length
40.54mm, Mylar
Tape Carrier
InsulKrimp Ring [190710227](#)
Tongue Terminal for
6 AWG Wire
InsulKrimp Brazed [190710230](#)
Ring Tongue
Terminal for 6 AWG
Wire, Expanded
Flare, Stud Size
5/16" (M8), Length
40.54mm, Mylar
Tape Carrier

This document was generated on 07/28/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19047-2040](#)