

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190540042](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: InsulKrimp Ring Tongue Terminal for 18-22 Heavy Duty AWG Wire, Vinyl, Stud Size 0.25"

Documents:

3D Model	Product Specification PS-19902-011-001 (PDF)
Drawing (PDF)	Product Specification PS-19902-013-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-19902-009-001 (PDF)	

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19054
Comments	Heavy Duty
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	InsulKrimp
Type	Ring
UPC	800753053953

Physical

Barrel Type	Closed
Color - Resin	Red
Flammability	94V-0
Insulation	PVC
Material - Metal	Copper
Material - Plating Mating	Tin
Net Weight	1.061/g
Packaging Type	Carton
Stud Size	1/4" (M6)
Temperature Range - Operating	105°C
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.68mm max.
Wire Size AWG	18, 20, 22
Wire Size mm ²	0.25-1.50

Solder Process Data


Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Engineering Number	A-222-14X
--------------------	-----------

Reference - Drawing Numbers

Product Specification	PS-19902-009-001, PS-19902-011-001, PS-19902-013-001
Sales Drawing	190540031-000

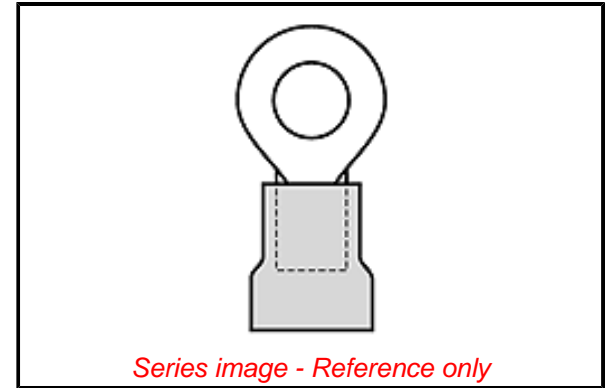

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[19054 Series](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
-------------	-----------

PremiumGrade	640010100
--------------	---------------------------

Hand Crimp Tool for Avikrimp and InsulKrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm² (Rings, Spades, Hooks, Block Spades and Flanged Spades)

Crimp Head for the AT-200 Pneumatic Hand Tool	640050100
---	---------------------------

ServiceGrade Hand 640160036
Crimp Tool for Field
Repair only, for
production use our
PremiumGrade Tool

This document was generated on 09/14/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19054-0042](#)