

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0190560015**  
**Status:** **Active**  
**Overview:** VersaKrimp Terminals and Splices  
**Description:** VersaKrimp Ring Tongue Terminal for 18-22 AWG Wire, Non-Insulated, Stud Size 8

**Documents:**

Drawing (PDF) Product Specification PS-19902-013-001 (PDF)  
Product Specification PS-19902-011-001 (PDF) RoHS Certificate of Compliance (PDF)

**Agency Certification**

CSA LR18689  
 UL E32244

**General**

Product Family Ring and Spade Terminals  
 Series 19056  
 Crimp Quality Equipment Yes  
 Overview VersaKrimp Terminals and Splices  
 Product Name VersaKrimp  
 Type Ring  
 UPC 800755063127

**Physical**

Barrel Type Closed - Brazed  
 Insulation None  
 Material - Metal Copper  
 Material - Plating Mating Tin  
 Net Weight 0.629/g  
 Packaging Type Carton  
 Stud Size 8 (M4)  
 Temperature Range - Operating 149°C  
 Termination Interface: Style Crimp or Compression  
 Wire Size AWG 18, 20, 22  
 Wire Size mm<sup>2</sup> 0.25-1.50

**Solder Process Data**


Lead-freeProcess Capability N/A

**Material Info**

Engineering Number A-321-08

**Reference - Drawing Numbers**

Product Specification PS-19902-011-001, PS-19902-013-001  
 Sales Drawing 190560006-000

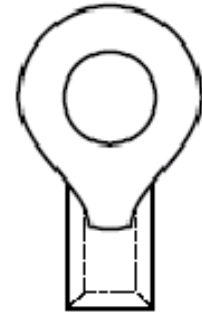

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**China RoHS**

**REACH SVHC**

Not Contained Per -  
 D(2021)4569-DC (8  
 July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

19056 Series

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

**Description**

**Product #**

PremiumGrade 640030100

Hand Crimp Tool for  
 Krimptite/Versakrimp  
 Terminals and  
 Splices, 10-22  
 AWG and 6.0mm<sup>2</sup> -  
 0.5mm<sup>2</sup>

Crimp Head for the 640070100

AT-200 Pneumatic  
 Hand Tool

ServiceGrade Hand 640160038

Crimp Tool - Ratchet

This document was generated on 09/27/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19056-0015](#)