

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0190580117](#)  
**Status:** **Active**  
**Overview:** Solderless Terminals  
**Description:** Avikrimp Ring Tongue Terminal for 14-16 Heavy Duty AWG Wire

**Documents:**

<a href="#">3D Model</a>	<a href="#">Product Specification PS-19902-011-001 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Product Specification PS-19902-013-001 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**Agency Certification**

CSA	LR18689
UL	E32244

**General**

Product Family	Ring and Spade Terminals
Series	<a href="#">19058</a>
Comments	Heavy Duty
Crimp Quality Equipment	Yes
Overview	<a href="#">Solderless Terminals</a>
Product Name	Avikrimp
Type	Ring
UPC	800753059924

**Physical**

Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	3.231/g
Packaging Type	Bag
Stud Size	3/8" (M9)
Wire Insulation Diameter	5.70mm max.
Wire Size AWG	14, 16
Wire Size mm <sup>2</sup>	1.30-2.00

**Solder Process Data**


Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

Engineering Number	B-840-38HD
--------------------	------------

**Reference - Drawing Numbers**

Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	190580016-000

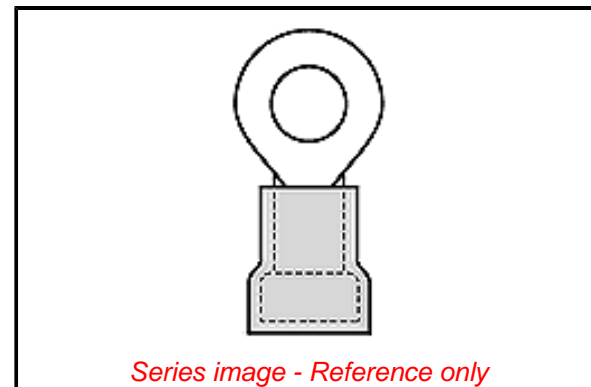

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[19058 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19058-0117](#)