

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190690040](#)
Status: **Active**
Overview: Solderless Terminals
Description: Krimptite Ring Tongue Terminal for 18-22 AWG Wire

Documents:

3D Model	Product Specification PS-19902-011-001 (PDF)
3D Model (PDF)	Product Specification PS-19902-013-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19069
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	Krimptite
Type	Ring
UPC	800755066340

Physical


Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.897/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	10 (M5)
Termination Interface: Style	Crimp or Compression
Wire Size AWG	18, 20, 22
Wire Size mm ²	0.35-0.80

Material Info

Engineering Number	AA-122-10
--------------------	-----------

Reference - Drawing Numbers

Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19069-004-001

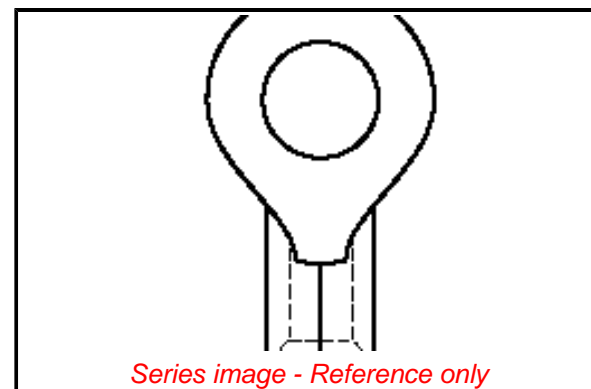

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Disodium 3,3'-[[1,1'-
Biphenyl]-4,4'-
Diylbis(Azo)
1,2-
Benzenedicarboxylic
acid, bis(3-
methylbutyl)
1,2-diethoxyethane
Dibutyltin-dichloride
1,3-Propanesultone
C.I. Direct Black 38
Ammonium-
pentadecafluorooctanoate
Disodium-octaborate
2-ethylhexyl 10-
ethyl-4,4-dioctyl-7-
oxo-8-oxa-3,
2-(2H-Benzotriazol-2-
yl)-4-(tert-butyl)-6-
(sec-b
Terphenyl,
hydrogenated
1,2-
Benzenedicarboxylic
acid, dihexyl ester,
bra
1,2-
Benzenedicarboxylic
acid, dipentyl ester, br
n-pentyl-
isopentylphthalate
Boric acid
Aluminosilicate
Refractory Ceramic
Fibres

China RoHS

Zirconia
Aluminosilicate
Refractory Ceramic
Fibr
Perfluorobutane
sulfonic acid (PFBS)
and its sal
Fluoranthene
Dodecachloropentacyclo[12.2.1.16,9.02,13.05,10]o
Diocetyl tin dilaurate,
stannane, dioctyl-,
bis(co
Perfluorononan-1-
oic acid
(2,2,3,3,4,4,5,5,6,6,7
Methylhexahydrophthalic
anhydride
reaction mass of
2-ethylhexyl 10-
ethyl-4,4-dioct
Perfluorohexane-1-
sulphonic acid and its
salts
Dodecamethylcyclohexasiloxane
Diarsenic-trioxide
Lead chromate
Lead chromate
molybdate sulfate red
Tris(2-chloroethyl)
phosphate
bis(2-methoxyethyl)
ether
Potassium
hydroxyoctaoxidizincatedichromate
Pentazinc-chromate-
octahydroxide
1,2-
Benzenedicarboxylic
acid, bis(2-
methoxyethyl
1,2-Dimethoxyethane
Diboron-trioxide
Cadmium-oxide
Cadmium-sulphide
Lead(II,IV)-oxide
Lead
Cadmium
pyrochlore, antimony
lead yellow
Lead-titanium-trioxide
Pentalead-tetraoxide-
sulphate
Trilead-dioxide-
phosphonate
Tetralead-trioxide-
sulphate
Dioxobis(stearato)trilead
Lead titanium
zirconium oxide
Fatty Acids, C16-18,
Lead Salts
Dicyclohexyl-
phthalate

bis(2-(2-methoxyethoxy)ethyl) ether

Halogen-Free Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[19069 Series](#)

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade Hand Crimp Tool for Krimptite/Versakrimp Terminals and Splices, 10-22 AWG and 6.0mm ² - 0.5mm ²	640030100
Crimp Head for the AT-200 Pneumatic Hand Tool	640070100
ServiceGrade Hand Crimp Tool - Ratchet	640160038

This document was generated on 10/12/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19069-0040](#)