

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0191150007](#)  
**Status:** **Active**  
**Overview:** Solderless Terminals  
**Description:** Avikrimp Snap Spade Terminal for 18-22 AWG Wire

**Documents:**

<a href="#">3D Model</a>	<a href="#">Product Specification PS-19902-011-001 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Product Specification PS-19902-013-001 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**Agency Certification**

CSA	LR18689
UL	E32244

**General**

Product Family	Ring and Spade Terminals
Series	<a href="#">19115</a>
Crimp Quality Equipment	Yes
Overview	<a href="#">Solderless Terminals</a>
Product Name	Avikrimp
Type	Spade Snap
UPC	800753091832

**Physical**


Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	0.730/g
Packaging Type	Bag
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Stud Size	5 (M3)
Wire Insulation Diameter	3.60mm max.
Wire Size AWG	18, 20, 22

**Material Info**

Engineering Number	AA-8704-05
--------------------	------------

**Reference - Drawing Numbers**

Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19115-001-001

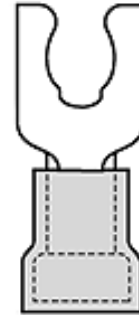

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[19115 Series](#)

**Application Tooling | [FAQ](#)**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

**Description**

**Product #**

PremiumGrade	<a href="#">640010100</a>
--------------	---------------------------

Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm<sup>2</sup> (Rings, Spades, Hooks, Block Spades and Flanged Spades)  
Crimp Head for the AT-200 Pneumatic Hand Tool

<a href="#">640050100</a>
---------------------------

ServiceGrade Hand 640160036  
Crimp Tool for Field  
Repair only, for  
production use our  
PremiumGrade Tool

This document was generated on 10/25/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19115-0007](#)