

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0191150043](#)  
**Status:** **Active**  
**Overview:** [Solderless Terminals](#)  
**Description:** Avikrimp Snap Spade Terminal for 10-12 AWG Wire

**Documents:**

<a href="#">3D Model</a>	<a href="#">Product Specification PS-19902-011-001 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Product Specification PS-19902-015-001 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**Agency Certification**

CSA	LR18689
UL	E32244

**General**

Product Family	Ring and Spade Terminals
Series	<a href="#">19115</a>
Crimp Quality Equipment	Yes
Overview	<a href="#">Solderless Terminals</a>
Product Name	Avikrimp
Type	Spade Snap
UPC	800753092402

**Physical**

Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	1.865/g
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Stud Size	5-6 (M3-3.5)
Wire Insulation Diameter	5.70mm max.
Wire Size AWG	10, 12

**Solder Process Data**


Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

Engineering Number	C-8710-06T
--------------------	------------

**Reference - Drawing Numbers**

Product Specification	PS-19902-011-001, PS-19902-015-001
Sales Drawing	191150041-000

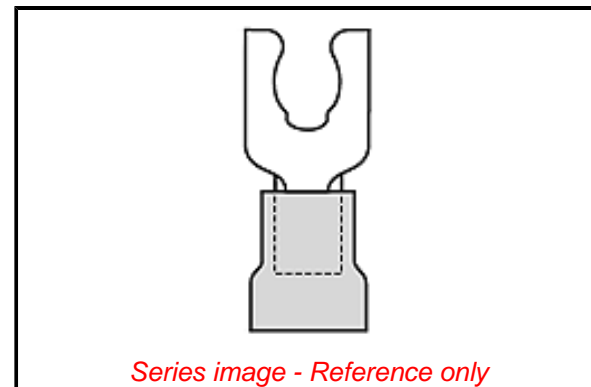

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[19115 Series](#)

**Application Tooling | [FAQ](#)**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

**Description**

**Product #**

ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	<a href="#">192880179</a>
Mini-Mac Pneumatic Applicator for Industrial Terminals 6-26 AWG	<a href="#">638851500</a>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19115-0043](#)