

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0191310004**
Status: **Active**
Overview: Solderless Terminals
Description: InsulKrimp Block Spade Tongue Terminal for 10 to 12 AWG Wire, Stud Size 8 (M4), Length 27.31mm

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-009-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series [19131](#)
 Crimp Quality Equipment Yes
 Overview [Solderless Terminals](#)
 Product Name InsulKrimp
 Type Spade Block
 UPC 800753101272

Physical

Barrel Type Closed
 Color - Resin Natural
 Flammability 94V-0
 Insulation PVC
 Material - Plating Mating Tin
 Net Weight 1.836/g
 Packaging Type Bag
 Plating min - Mating 0.305µm
 Plating min - Termination 0.305µm
 Stud Size 8 (M4)
 Termination Interface: Style Crimp or Compression
 Wire Insulation Diameter 6.40mm max.
 Wire Size AWG 10, 12
 Wire Size mm² 3.30-5.00

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number C-2105-08X

Reference - Drawing Numbers

Product Specification PS-19902-009-001, PS-19902-011-001, PS-19902-013-001
 Sales Drawing 191310010-000

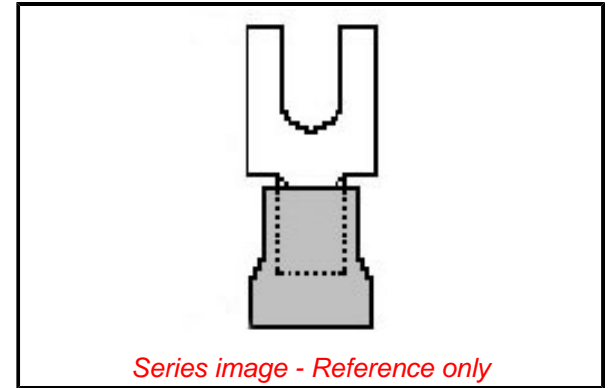

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2021)4569-DC (8
 July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[19131 Series](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

PremiumGrade [640010100](#)

Hand Crimp Tool for Avikrimp and InsulKrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm² (Rings, Spades, Hooks, Block Spades and Flanged Spades)

PremiumGrade [640010300](#)

Hand Crimp Tool for InsulKrimp Terminals and Splices, 10-22

AWG (Rings,
Spades, Hooks,
Block Spades and
Flanged Spades)
Crimp Head for the 640050100
AT-200 Pneumatic
Hand Tool
Crimp Head for the 640050300
AT-200 Pneumatic
Hand Tool
ServiceGrade Hand 640160036
Crimp Tool for Field
Repair only, for
production use our
PremiumGrade Tool

This document was generated on 08/31/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19131-0004](#)