

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0191410021](#)  
**Status:** **Active**  
**Overview:** [Solderless Terminals](#)  
**Description:** Krimptite Spade Tongue Terminal for 18-22 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier

**Documents:**

[Drawing \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)  
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR18689  
 UL E32244

**General**

Product Family Ring and Spade Terminals  
 Series [19141](#)  
 Crimp Quality Equipment Yes  
 Overview [Solderless Terminals](#)  
 Product Name Krimptite  
 Type Spade  
 UPC 800753103191

**Physical**

Barrel Type Closed  
 Insulation None  
 Material - Plating Mating Tin  
 Net Weight 0.549/g  
 Packaging Type Adhesive Tape on Reel  
 Stud Size 6 (M3.5)  
 Wire Size AWG 18, 20, 22  
 Wire Size mm<sup>2</sup> 0.25-1.50

**Electrical**

Voltage - Maximum 600V

**Solder Process Data**


Lead-free Process Capability N/A

**Material Info**

Engineering Number AA-135-06T

**Reference - Drawing Numbers**

Product Specification PS-19902-011-001, PS-19902-015-001  
 Sales Drawing AACD10303-001

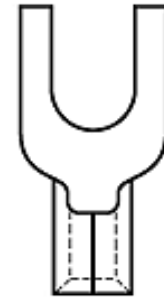

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Contained Per -  
 D(2021)4569-DC (8  
 July 2021)  
 Disodium 3,3'-[[1,1'-  
 Biphenyl]-4,4'-  
 Diylbis(Azo)  
 1,2-  
 Benzenedicarboxylic  
 acid, bis(3-  
 methylbutyl)  
 1,2-diethoxyethane  
 Dibutyltin-dichloride  
 1,3-Propanesultone  
 C.I. Direct Black 38  
 Ammonium-  
 pentadecafluorooctanoate  
 Disodium-octaborate  
 2-ethylhexyl 10-  
 ethyl-4,4-dioctyl-7-  
 oxo-8-oxa-3,  
 2-(2H-Benzotriazol-2-  
 yl)-4-(tert-butyl)-6-  
 (sec-b  
 Terphenyl,  
 hydrogenated  
 1,2-  
 Benzenedicarboxylic  
 acid, dihexyl ester,  
 bra  
 1,2-  
 Benzenedicarboxylic  
 acid, dipentyl ester, br  
 n-pentyl-  
 isopentylphthalate  
 Boric acid  
 Aluminosilicate  
 Refractory Ceramic  
 Fibres

**China RoHS**

Zirconia  
Aluminosilicate  
Refractory Ceramic  
Fibr  
Perfluorobutane  
sulfonic acid (PFBS)  
and its sal  
Fluoranthene  
Dodecachloropentacyclo[12.2.1.16,9.02,13.05,10]o  
Diocetyl tin dilaurate,  
stannane, dioctyl-,  
bis(co  
Perfluorononan-1-  
oic acid  
(2,2,3,3,4,4,5,5,6,6,7  
Methylhexahydrophthalic  
anhydride  
reaction mass of  
2-ethylhexyl 10-  
ethyl-4,4-dioct  
Perfluorohexane-1-  
sulphonic acid and its  
salts  
Dodecamethylcyclohexasiloxane  
Diarsenic-trioxide  
Lead chromate  
Lead chromate  
molybdate sulfate red  
Tris(2-chloroethyl)  
phosphate  
bis(2-methoxyethyl)  
ether  
Potassium  
hydroxyoctaoxidizincatedichromate  
Pentazinc-chromate-  
octahydroxide  
1,2-  
Benzenedicarboxylic  
acid, bis(2-  
methoxyethyl  
1,2-Dimethoxyethane  
Diboron-trioxide  
Cadmium-oxide  
Cadmium-sulphide  
Lead(II,IV)-oxide  
Lead  
Cadmium  
pyrochlore, antimony  
lead yellow  
Lead-titanium-trioxide  
Pentalead-tetraoxide-  
sulphate  
Trilead-dioxide-  
phosphonate  
Tetralead-trioxide-  
sulphate  
Dioxobis(stearato)trilead  
Lead titanium  
zirconium oxide  
Fatty Acids, C16-18,  
Lead Salts  
Dicyclohexyl-  
phthalate

bis(2-(2-methoxyethoxy)ethyl)  
ether

**Halogen-Free  
Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[19141](#) Series

**Application Tooling | [FAQ](#)**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

Description	Product #
-------------	-----------

ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	<a href="#">190270034</a>
Mini-Mac Applicator	<a href="#">638853800</a>

This document was generated on 09/14/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19141-0021](#)