

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0191600039**
Status: **Active**
Overview: [Splices](#)
Description: Twist Lock Splice for 14-22 AWG Wire, Grey

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-013-001 \(PDF\)](#)

Agency Certification

CSA LR700095
 UL E32244

General

Product Family Splices
 Series [19160](#)
 Crimp Quality Equipment Yes
 Overview [Splices](#)
 Product Name Closed-End Twist Lock
 UPC 800753110434

Physical

Barrel Type Closed
 Color - Resin Grey
 Flammability 94V-2
 Insulation Nylon (PA)
 Material - Metal Copper
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 0.431/g
 Packaging Type Bag
 Temperature Range - Operating 105°C
 Wire Insulation Diameter 6.60mm max.
 Wire Size AWG 14, 16, 18, 20, 22

Electrical


Voltage - Maximum 300V

Material Info

Engineering Number TL-G

Reference - Drawing Numbers

Product Specification PS-19902-013-001
 Sales Drawing SD-19160-005-001

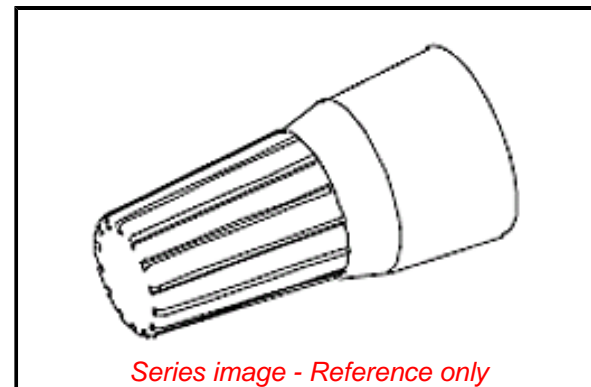

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2021)4569-DC (8
 July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[19160 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19160-0039](#)