

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0191830019**  
**Status:** **Active**  
**Overview:** Solderless Terminals  
**Description:** Avikrimp Hook Tongue Terminal for 10-12 AWG Wire, Stud Size 10 (M5)

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-19902-011-001 \(PDF\)](#)

**Agency Certification**

CSA LR18689  
 UL E32244

**General**

Product Family Ring and Spade Terminals  
 Series [19183](#)  
 Crimp Quality Equipment Yes  
 Overview [Solderless Terminals](#)  
 Product Name Avikrimp  
 Type Hook  
 UPC 800753036512

**Physical**


Barrel Type Closed  
 Flammability 94V-2  
 Insulation Nylon (PA)  
 Material - Plating Mating Tin  
 Net Weight 2.123/g  
 Packaging Type Bag  
 Plating min - Mating 2.540µm  
 Plating min - Termination 2.540µm  
 Stud Size 10 (M5)  
 Termination Interface: Style Crimp or Compression  
 Wire Insulation Diameter 5.72mm max.  
 Wire Size AWG 10, 12

**Material Info**

Engineering Number C-811-10

**Reference - Drawing Numbers**

Product Specification PS-19902-011-001  
 Sales Drawing 1302-08, 191830013-000

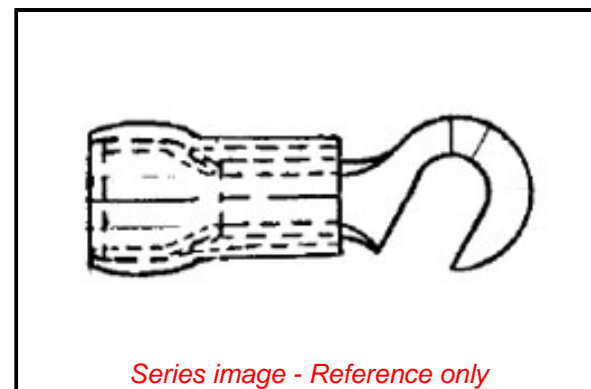

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**China RoHS**

**REACH SVHC**

Not Contained Per -  
 D(2021)4569-DC (8  
 July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

19183 Series

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

| Description  | Product #                 |
|--|---------------------------|
| PremiumGrade Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm <sup>2</sup> (Rings, Spades, Hooks, Block Spades and Flanged Spades) | <a href="#">640010100</a> |
| Crimp Head for the AT-200 Pneumatic Hand Tool  | <a href="#">640050100</a> |

ServiceGrade Hand 640160036  
Crimp Tool for Field  
Repair only, for  
production use our  
PremiumGrade Tool

This document was generated on 09/22/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19183-0019](#)