

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0192020051**
Status: **Active**
Overview: [Splices](#)
Description: NylaKrimp Butt Splice for 10-12 AWG Wire, Tape and Reel

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family [Splices](#)
 Series [19202](#)
 Crimp Quality Equipment Yes
 Overview [Splices](#)
 Product Name Butt, NylaKrimp
 UPC 800753048256

Physical


Barrel Type Closed - Brazed
 Color - Resin Yellow
 Flammability 94V-2
 Insulation Nylon (PA)
 Material - Metal Copper
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 2.858/g
 Packaging Type Adhesive Tape on Reel
 Wire Size AWG 10, 12

Material Info

Engineering Number CS-N-346T

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-015-001
 Sales Drawing 60002-11C-001

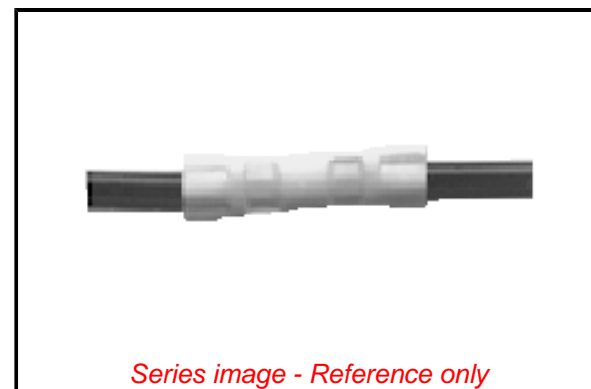

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2020)9139-DC (19
 Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[19202 Series](#)

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

ATP Crimp Dies
 for the Tape Crimp
 Module and ATP-101
 & 301 Press

[192880289](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19202-0051](#)