

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **31408-1200**
Status: **Active**
Overview: Stac64™ Single, Multi-Pocket and Hybrid Header System
Description: USCAR 2.54mm Pitch Receptacle, 20 Circuits, Polarization A, Black

Documents:

[3D Model](#) [Application Specification AS-34691-100 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-31408-100 \(PDF\)](#)

General

Product Family	Crimp Housings
Series	<u>31408</u>
Application	Power, Wire-to-Board
Comments	Polarization A
Overview	<u>Stac64™ Single, Multi-Pocket and Hybrid Header System</u>
Product Name	USCAR
UPC	822348405404

Physical

Circuits (maximum)	20
Circuits Detail	20
Color - Resin	Black
Gender	Female
Glow-Wire Compliant	No
Keying to Mating Part	None
Lock to Mating Part	No
Material - Resin	Modified Polystyrene
Net Weight	6.484/g
Number of Rows	2
Packaging Type	Carton
Panel Mount	No
Pitch - Mating Interface	2.54mm
Polarized to Mating Part	Yes
Ports	1
Stackable	No
Temperature Range - Operating	-40°C to +100°C

Electrical

Current - Maximum per Contact	10.2A
-------------------------------	-------

Material Info

Reference - Drawing Numbers

Application Specification	AS-34691-100
Product Specification	PS-31408-100
Sales Drawing	SD-31408-900

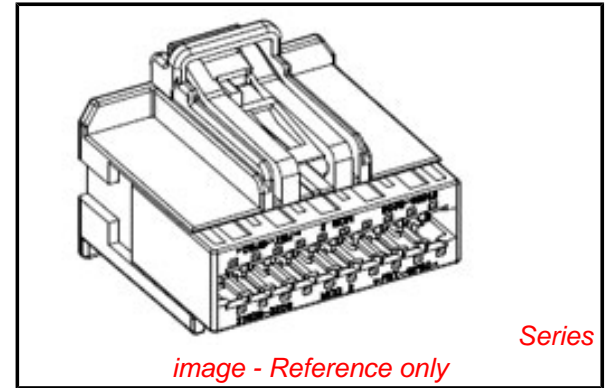


image - Reference only

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

31408Series

Mates With

34691 Stac64 Right Angle Assembly. [34690](#)
 Stac64 Vertical Assembly

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[31408-1200](#)