

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [31408-1202](#)  
**Status:** **Active**  
**Overview:** [Stac64™ Single, Multi-Pocket and Hybrid Header System](#)  
**Description:** [USCAR 2.54mm Pitch Receptacle, 20 Circuits, Polarization C, Brown](#)

**Documents:**

[3D Model](#) [Application Specification AS-34691-100 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-31408-100 \(PDF\)](#)

**General**

|                |   |
|----------------|---|
| Product Family | Crimp Housings  |
| Series         | <a href="#">31408</a>   |
| Application    | Power, Wire-to-Board  |
| Comments       | Polarization C  |
| Overview       | <a href="#">Stac64™ Single, Multi-Pocket and Hybrid Header System</a> |
| Product Name   | USCAR   |
| UPC            | 822348432066  |

**Physical**

|                               |                      |
|-------------------------------|----------------------|
| Circuits (maximum)            | 20                   |
| Circuits Detail               | 20                   |
| Color - Resin                 | Brown                |
| Gender                        | Female               |
| Glow-Wire Compliant           | No                   |
| Keying to Mating Part         | None                 |
| Lock to Mating Part           | No                   |
| Material - Resin              | Modified Polystyrene |
| Net Weight                    | 6.484/g              |
| Number of Rows                | 2                    |
| Packaging Type                | Carton               |
| Panel Mount                   | No                   |
| Pitch - Mating Interface      | 2.54mm               |
| Polarized to Mating Part      | Yes                  |
| Ports                         | 1                    |
| Stackable                     | No                   |
| Temperature Range - Operating | -40°C to +100°C      |


**Electrical**

|                               |       |
|-------------------------------|-------|
| Current - Maximum per Contact | 10.2A |
|-------------------------------|-------|

**Material Info**

**Reference - Drawing Numbers**

|                           |              |
|---------------------------|--------------|
| Application Specification | AS-34691-100 |
| Product Specification     | PS-31408-100 |
| Sales Drawing             | SD-31408-900 |

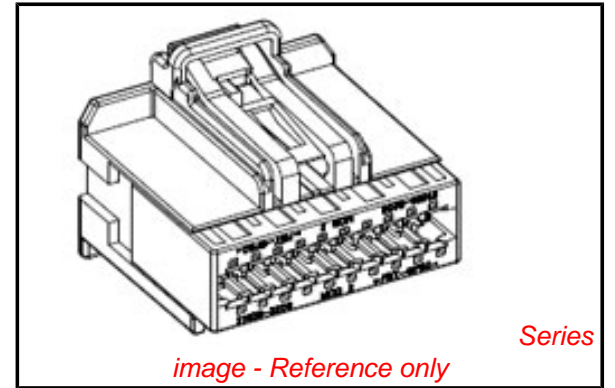

*image - Reference only*

**EU RoHS**

**ELV and RoHS Compliant**

**REACH SVHC**

Not Reviewed

**Low-Halogen Status**

**Low-Halogen**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

[31408Series](#)

**Mates With**

[34691 Stac64 Right Angle Assembly](#). [34690 Stac64 Vertical Assembly](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[31408-1202](#)