

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0350230008](#)
Status: **Active**
Overview: Board-in Connectors
Description: 2.00mm Pitch, Board-In Crimp Housing, Right-Angle, 8 Circuits, Natural

Documents:

3D Model	Product Specification PS-35023-001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-35023-001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	35023
Application	Signal, Wire-to-Board
Overview	Board-in Connectors
Product Name	Board-in
UPC	800753514515

Physical

Circuits (maximum)	8
Color - Resin	Natural
Flammability	94V-0
Gender	N/A
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	0.151/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-40° to +105°C


Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-35023-001-001
Product Specification	PS-35023-001-001
Sales Drawing	SD-35023-001-001

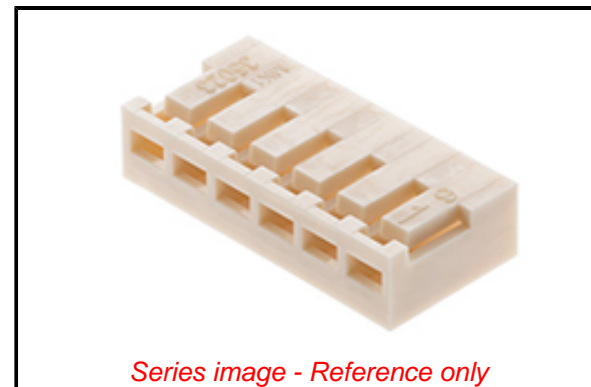

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[35023](#) Series

Use With

Straight Terminal [350449102](#) , [350449260](#)

Right Angle Terminal [350211201](#) ,
[350211301](#) , [350211360](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[35023-0008](#)