

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0350289010](#)
Status: **Active**
Description: 1.78mm Tab Terminal, Female, 18-22 AWG (0.82-0.33mm²), Pre-Tin Plated, Reel

Documents:

Drawing (PDF)	Packaging Specification PK-35028-001-001 (PDF)
Product Specification PS-35028-001-001 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-35127-001-001 (PDF)	

General

Product Family	Crimp Terminals
Series	35028
Application	Power, Wire-to-Component, Wire-to-Wire
Crimp Quality Equipment	Yes
Product Name	N/A
UPC	800753289772


Physical

Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.306/g
Packaging Type	Reel
Plating min - Mating	0.813µm
Plating min - Termination	0.813µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.60mm max.
Wire Size AWG	18, 20, 22
Wire Size mm ²	N/A

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-35028-001-001
Product Specification	PS-35028-001-001, PS-35127-001-001
Sales Drawing	SD-35028-XXXX

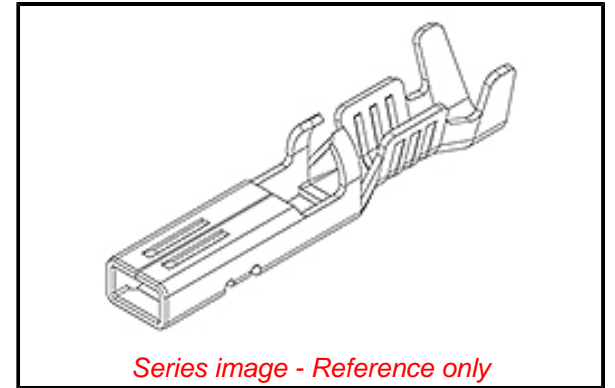

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/88/2018 (15
January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

35028 Series

Mates With

2.54mm Male Tab

Use With

35153

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[35028-9010](#)