

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0357607110](#)  
**Status:** **Active**  
**Overview:** [Splices](#)  
**Description:** Wire Splice, 16-20 AWG, Post-Tin Plating

**Documents:**

[Drawing \(PDF\)](#) [Packaging Specification PK-35760-001-001 \(PDF\)](#)  
[Product Specification PS-35760-003-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Splices
Series	<a href="#">35760</a>
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	<a href="#">Splices</a>
Product Name	N/A
UPC	800753514737

**Physical**

Barrel Type	Open
Insulation	None
Material - Metal	Brass
Net Weight	0.790/g
Packaging Type	Reel
Temperature Range - Operating	-30°C to +105°C
Wire Insulation Diameter	3.51mm
Wire Size AWG	16, 18, 20
Wire Size mm <sup>2</sup>	0.50-1.50


**Electrical**

Voltage - Maximum	200V AC (RMS)/DC
-------------------	------------------

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	PK-35760-001-001
Product Specification	PS-35760-003-001
Sales Drawing	SD-35760-002

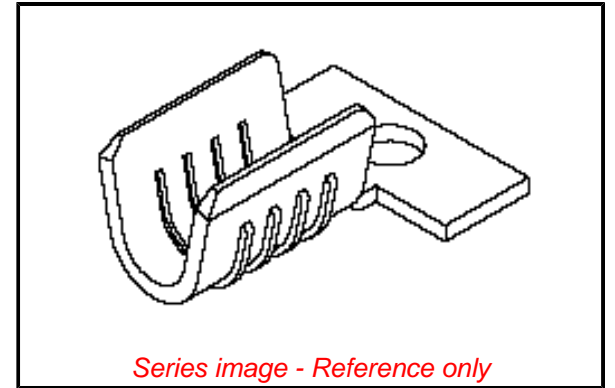

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
-ED/01/2018 (15  
January 2018)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[35760 Series](#)

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[35760-7110](#)