

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0386006632](#)  
**Status:** **Active**  
**Overview:** [Beau Barrier Strips](#)  
**Description:** 6.35mm Pitch Beau PCB Tri-Barrier Terminal Strip, without Mounting Ends, 300V, 32 Circuits

**Documents:**

[3D Model](#) [3D Model \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family Terminal Blocks  
 Series [38600](#)  
 Application N/A  
 Component Type One Piece  
 Overview [Beau Barrier Strips](#)  
 Product Name Fixed Mount Barrier  
 Type Barrier Strip  
 UPC 800756243658

**Physical**

Circuits (Loaded) 32  
 Circuits (maximum) 32  
 Color - Resin Black  
 Entry Angle Horizontal  
 Lock to Mating Part None  
 Material - Metal Brass  
 Material - Plating Mating Tin  
 Material - Plating Termination Tin  
 Material - Resin Polyester Alloy  
 Number of Rows 1  
 Orientation Horizontal  
 PC Tail Length 5.10mm  
 PCB Thickness - Recommended 3.18mm  
 Panel Mount No  
 Pitch - Mating Interface 6.35mm  
 Pitch - Termination Interface 6.35mm  
 Polarized to Mating Part No  
 Shrouded Tri-Barrier  
 Stackable No  
 Surface Mount Compatible (SMC) No  
 Temperature Range - Operating -40° to +130°C  
 Wire Size AWG 18, 20, 22

**Electrical**


Current - Maximum per Contact 10.0A  
 Voltage - Maximum 300V

**Material Info**

Engineering Number 60532-C

**Reference - Drawing Numbers**

Sales Drawing SD-38600-001

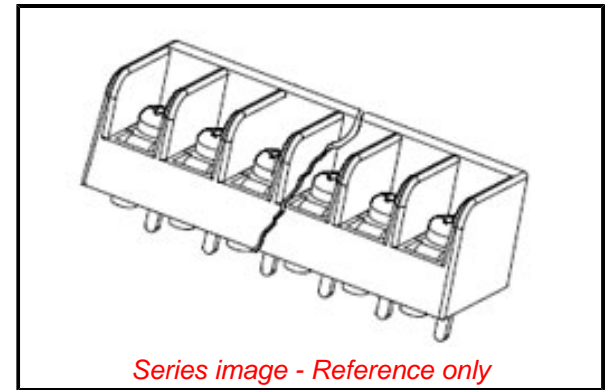

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[38600 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[38600-6632](#)