

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0387200308

Status:


Active

Overview:

Beau Barrier Strips

Description:

9.53mm Pitch Beau PCB Terminal Strip, Screw Terminal, 8 Circuits

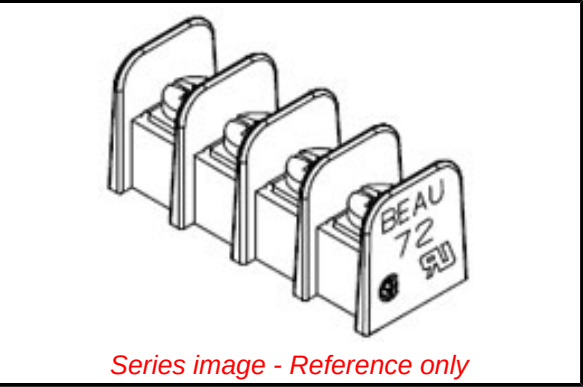

Series image - Reference only

Documents:	
3D Model	Product Specification PS-38710-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
3D Model (PDF)	

General	
Product Family	Terminal Blocks
Series	38720
Application	N/A
Component Type	One Piece
Overview	Beau Barrier Strips
Product Name	Fixed Mount Barrier
Type	Barrier Strip
UPC	800756322575
Physical	
Circuits (Loaded)	8
Circuits (maximum)	8
Color - Resin	Black
Entry Angle	Horizontal
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Thermoplastic Polyurethane
Number of Rows	1
Orientation	Horizontal
PC Tail Length	4.80mm
PCB Thickness - Recommended	3.18mm
Panel Mount	No
Pitch - Mating Interface	9.53mm
Pitch - Termination Interface	9.53mm
Plating min - Mating	3.810µm
Plating min - Termination	3.810µm
Polarized to Mating Part	No
Shrouded	Dual-Barrier
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +130°C
Wire Size AWG	14, 16, 18, 20, 22
Wire Size mm²	0.50-1.50
Electrical	
Current - Maximum per Contact	15.0A
Voltage - Maximum	300V
Material Info	
Engineering Number	72108-C
Reference - Drawing Numbers	
Product Specification	PS-38710-001-001
Sales Drawing	SD-38720-013

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

38720 Series

This document was generated on 07/31/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[38720-0308](#)