

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0391002210](#)
Status: **Active**
Overview: Eurostyle Two-Screw Barrier Strips
Description: 12.00mm Pitch Beau Eurostyle Two-Screw Terminal Strips, 10 Circuits

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Terminal Blocks
Series	39100
Application	Wire-to-Wire
Component Type	One Piece
Overview	Eurostyle Two-Screw Barrier Strips
Product Name	Eurostyle Two Screw
Type	Barrier Strip
UPC	78172545244

Physical

Circuits (Loaded)	10
Circuits (maximum)	10
Color - Resin	White
Entry Angle	Horizontal
Lock to Mating Part	None
Material - Metal	Stainless Steel
Material - Resin	Nylon
Number of Rows	2
Orientation	Vertical
PCB Retention	Yes
Panel Mount	Mounting Holes Between Circuit
Pitch - Mating Interface	12.00mm
Pitch - Termination Interface	12.00mm
Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	10, 12, 14, 16, 18, 20, 8

Electrical


Current - Maximum per Contact	40.0A
Voltage - Maximum	600V

Material Info

Engineering Number	M800-03-10-5-M1
--------------------	-----------------

Reference - Drawing Numbers

Sales Drawing	SD-39100-015-001
---------------	------------------

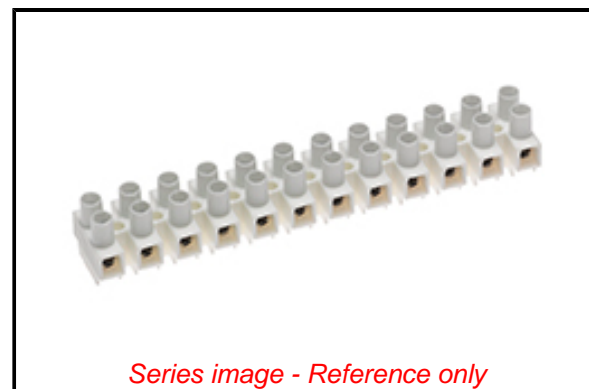

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[39100 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39100-2210](#)