

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0393730003](#)
Status: **Active**
Overview: [Eurostyle Terminal Blocks](#)
Description: 7.50mm Beau Eurostyle Horizontal PCB Header, Closed Ends, 3 Circuits

Documents:

3D Model	3D Model (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

UL	E48521
----	--------

General

Product Family	Terminal Blocks
Series	39373
Application	N/A
Component Type	PCB Header
Overview	Eurostyle Terminal Blocks
Product Name	Eurostyle Pluggable
Type	Euro Block
UPC	822348042067

Physical

Circuits (Loaded)	3
Circuits (maximum)	3
Entry Angle	90° Angle
Flammability	94V-0
Lock to Mating Part	None
Number of Rows	1
Orientation	Right Angle
PC Tail Length	3.50mm
PCB Retention	None
Panel Mount	No
Pitch - Mating Interface	7.50mm
Pitch - Termination Interface	7.50mm
Polarized to Mating Part	Yes
Shrouded	Closed Ends
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	110°C
Wire Size AWG	N/A

Electrical


Current - Maximum per Contact	15.0A
Voltage - Maximum	300V

Material Info

Engineering Number	MX-CIM039P3-0N
--------------------	----------------

Reference - Drawing Numbers

Sales Drawing	SD-39373-001-001
---------------	------------------

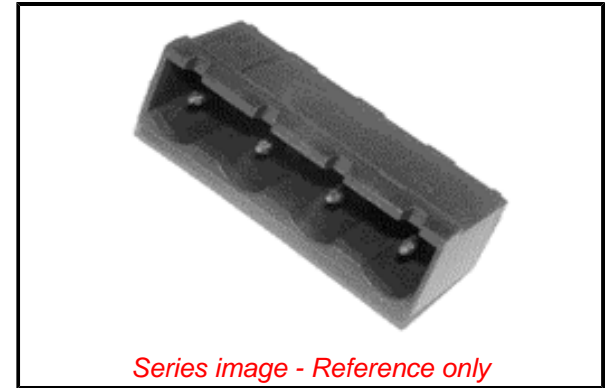

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[39373](#) Series

Mates With

[39371](#) , [39374](#) Plugs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39373-0003](#)