

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0393730012](#)
Status: **Active**
Overview: [Eurostyle Terminal Blocks](#)
Description: 7.50mm Beau Eurostyle Horizontal PCB Header, Closed Ends, 12 Circuits

Documents:

[3D Model](#) [3D Model \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks
 Series [39373](#)
 Application N/A
 Component Type PCB Header
 Overview [Eurostyle Terminal Blocks](#)
 Product Name Eurostyle Pluggable
 Type Euro Block
 UPC 822348042159

Physical

Circuits (Loaded) 12
 Circuits (maximum) 12
 Entry Angle 90° Angle
 Flammability 94V-0
 Lock to Mating Part None
 Number of Rows 1
 Orientation Right Angle
 PC Tail Length 3.50mm
 PCB Retention None
 Panel Mount No
 Pitch - Mating Interface 7.50mm
 Pitch - Termination Interface 7.50mm
 Polarized to Mating Part Yes
 Shrouded Closed Ends
 Stackable No
 Surface Mount Compatible (SMC) No
 Temperature Range - Operating 110°C
 Wire Size AWG N/A

Electrical


Current - Maximum per Contact 15.0A
 Voltage - Maximum 300V

Material Info

Engineering Number MX-CIM129P3-0N

Reference - Drawing Numbers

Sales Drawing SD-39373-001

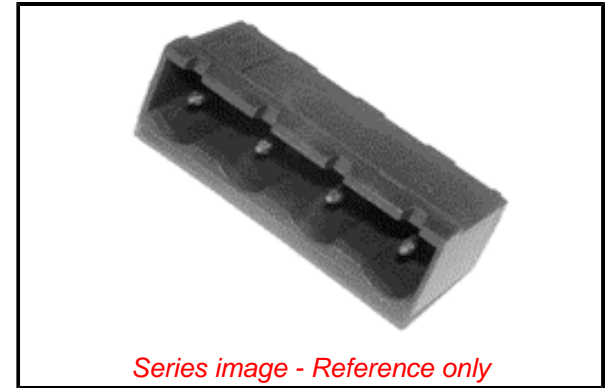

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[39373](#) Series

Mates With

[39371](#) , [39374](#) Plugs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39373-0012](#)