

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0393740903](#)
Status: **Active**
Overview: [Eurostyle Terminal Blocks](#)
Description: 7.50mm Beau Eurostyle Pluggable PCB Terminal Block, 270° Wire Entry, 3 Circuits

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks
 Series [39374](#)
 Application N/A
 Component Type Plug
 Overview [Eurostyle Terminal Blocks](#)
 Product Name Eurostyle Pluggable
 Type Euro Block
 UPC 822348047369

Physical

Circuits (Loaded) 3
 Entry Angle 270° Angle
 Flammability 94V-0
 Lock to Mating Part None
 Number of Rows 1
 Orientation Vertical
 PCB Retention N/A
 Panel Mount No
 Pitch - Mating Interface 7.50mm
 Pitch - Termination Interface 7.50mm
 Polarized to Mating Part Yes
 Stackable Yes
 Temperature Range - Operating 110°C
 Wire Size AWG 12, 14, 16, 18, 20, 22, 24, 26, 28, 30
 Wire Size mm² 0.05-2.50

Electrical


Current - Maximum per Contact 15.0A
 Voltage - Maximum 300V

Material Info

Engineering Number MX-CVF030R3-0N

Reference - Drawing Numbers

Sales Drawing SD-39374-002

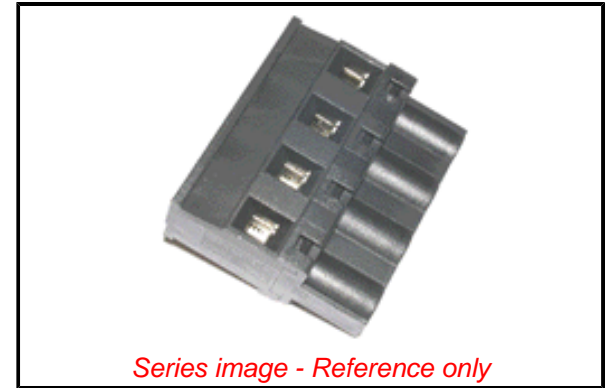

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[39374](#) Series

Mates With

[39372](#) , [39373](#) Headers

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39374-0903](#)