

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0393740909](#)  
**Status:** **Active**  
**Overview:** [Eurostyle Terminal Blocks](#)  
**Description:** 7.50mm Beau Eurostyle Pluggable PCB Terminal Block, 270° Wire Entry, 9 Circuits

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

UL E48521

**General**

Product Family Terminal Blocks  
 Series [39374](#)  
 Application N/A  
 Component Type Plug  
 Overview [Eurostyle Terminal Blocks](#)  
 Product Name Eurostyle Pluggable  
 Type Euro Block  
 UPC 822348050321

**Physical**

Circuits (Loaded) 9  
 Entry Angle 270° Angle  
 Flammability 94V-0  
 Lock to Mating Part None  
 Number of Rows 1  
 Orientation Vertical  
 PCB Retention N/A  
 Panel Mount No  
 Pitch - Mating Interface 7.50mm  
 Pitch - Termination Interface 7.50mm  
 Polarized to Mating Part Yes  
 Stackable Yes  
 Temperature Range - Operating 110°C  
 Wire Size AWG 12, 14, 16, 18, 20, 22, 24, 26, 28, 30  
 Wire Size mm<sup>2</sup> 0.05-2.50

**Electrical**


Current - Maximum per Contact 15.0A  
 Voltage - Maximum 300V

**Material Info**

Engineering Number MX-CVF090R3-0N

**Reference - Drawing Numbers**

Sales Drawing SD-39374-002

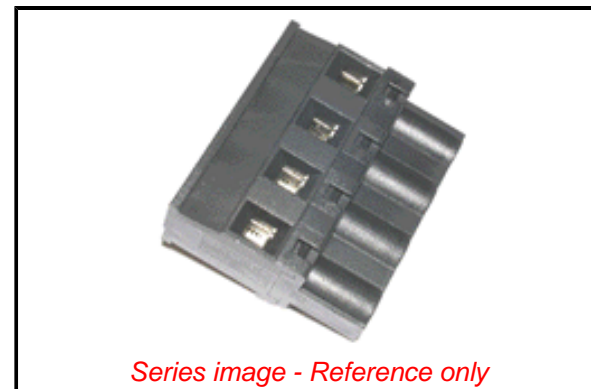

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[39374](#) Series

**Mates With**

[39372](#) , [39373](#) Headers

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39374-0909](#)