

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0394260005](#)
Status: **Active**
Overview: Eurostyle Terminal Blocks
Description: 12.00mm Pitch Beau EuroMax Right-Angle PCB Header, Closed Ends, 5 Circuits, with Threaded Retention Inserts

Documents:

[3D Model](#) [3D Model \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Terminal Blocks
Series	39426
Application	N/A
Component Type	PCB Header
Overview	Eurostyle Terminal Blocks
Product Name	EuroMax Pluggable
Type	Euro Block
UPC	822348755677

Physical

Circuits (Loaded)	5
Color - Resin	Black
Entry Angle	N/A
Lock to Mating Part	Yes
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Number of Rows	1
Orientation	Right Angle
PC Tail Length	4.30mm
PCB Retention	Yes
PCB Thickness - Recommended	3.20mm
Panel Mount	No
Pitch - Mating Interface	12.00mm
Pitch - Termination Interface	12.00mm
Plating min - Mating	3.810µm
Plating min - Termination	3.810µm
Polarized to Mating Part	Yes
Shrouded	Closed Ends
Stackable	No
Temperature Range - Operating	130°C
Termination Interface: Style	Through Hole
Wire Size AWG	N/A

Electrical


Current - Maximum per Contact	85.0A
Voltage - Maximum	600V

Material Info

Engineering Number	425905
--------------------	--------

Reference - Drawing Numbers

Sales Drawing	SD-39426-001-000
---------------	------------------

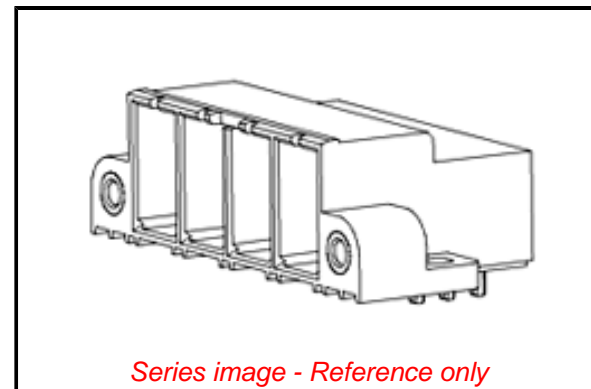

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[39426](#) Series

Mates With

[39421](#) Plugs

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39426-0005](#)