

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395051509

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

3.50mm Pitch Eurostyle Vertical PCB Header, with Threaded Retention Inserts, Gold (Au) Plated, 9 Circuits

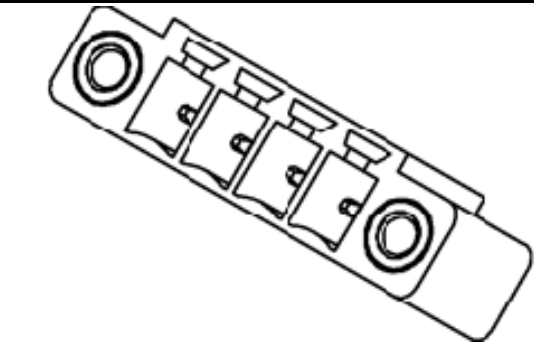

Series image - Reference only

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

|                      |  |                           |
|----------------------|--|---------------------------|
| Agency Certification |  |                           |
| UL                   |  | E48521                    |
| General              |  |                           |
| Product Family       |  | Terminal Blocks           |
| Series               |  | 39505                     |
| Application          |  | N/A                       |
| Component Type       |  | PCB Header                |
| Overview             |  | Eurostyle Terminal Blocks |
| Product Name         |  | ESE, Eurostyle Pluggable  |
| Type                 |  | Euro Block                |
| UPC                  |  | 822350446853              |

|                               |  |                |
|-------------------------------|--|----------------|
| Physical                      |  |                |
| Circuits (Loaded)             |  | 9              |
| Entry Angle                   |  | N/A            |
| Lock to Mating Part           |  | Yes            |
| Number of Rows                |  | 1              |
| Orientation                   |  | Vertical       |
| PC Tail Length                |  | 3.50mm         |
| PCB Thickness - Recommended   |  | 2.50mm         |
| Panel Mount                   |  | No             |
| Pitch - Mating Interface      |  | 3.50mm         |
| Pitch - Termination Interface |  | 3.50mm         |
| Polarized to Mating Part      |  | Yes            |
| Shrouded                      |  | Fully          |
| Stackable                     |  | No             |
| Temperature Range - Operating |  | -40° to +105°C |
| Wire Size AWG                 |  | N/A            |

|                               |  |      |
|-------------------------------|--|------|
| Electrical                    |  |      |
| Current - Maximum per Contact |  | 8.0A |
| Voltage - Maximum             |  | 300V |

Material Info

|                             |  |                                |
|-----------------------------|--|--------------------------------|
| Reference - Drawing Numbers |  |                                |
| Product Specification       |  | PS-39500-001-001               |
| Sales Drawing               |  | SD-39501-002, SD-39505-001-001 |

EU ELV

Not Relevant

|              |            |
|--------------|------------|
| EU RoHS      | China RoHS |
| Not Reviewed |            |
| REACH SVHC   |            |
| Not Reviewed |            |
| Halogen-Free |            |
| Status       |            |
| Not Reviewed |            |

For more information, please visit [Contact US](#)

|                 |              |
|-----------------|--------------|
| China ROHS      | Not Relevant |
| ELV             | Not Relevant |
| RoHS Phthalates | Not Reviewed |

Search Parts in this Series

39505 Series

Mates With

Most 3.50mm Pitch Industry Standard Plugs, 39504 Horizontal Plug with Retention Screws, 39507 Vertical Plug with Retention Screws

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39505-1509