

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0395061006](#)
Status: **Active**
Overview: Eurostyle Terminal Blocks
Description: 3.50mm Pitch Eurostyle Horizontal PCB Header, with Threaded Retention Inserts, 6 Circuits

Documents:

[3D Model](#) [Product Specification PS-39500-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[3D Model \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks
 Series [39506](#)
 Application N/A
 Component Type PCB Header
 Overview [Eurostyle Terminal Blocks](#)
 Product Name ESE, Eurostyle Pluggable
 Type Euro Block
 UPC 822350450430

Physical

Circuits (Loaded) 6
 Entry Angle N/A
 Lock to Mating Part Yes
 Net Weight 2.160/g
 Number of Rows 1
 Orientation Horizontal
 PC Tail Length 3.50mm
 PCB Thickness - Recommended 2.50mm
 Panel Mount No
 Pitch - Mating Interface 3.50mm
 Pitch - Termination Interface 3.50mm
 Polarized to Mating Part Yes
 Shrouded Fully
 Stackable No
 Temperature Range - Operating -40° to +105°C
 Wire Size AWG N/A


Electrical

Current - Maximum per Contact 8.0A
 Voltage - Maximum 300V

Material Info

Reference - Drawing Numbers

Product Specification PS-39500-001-001
 Sales Drawing SD-39501-002-001, SD-39506-001-001

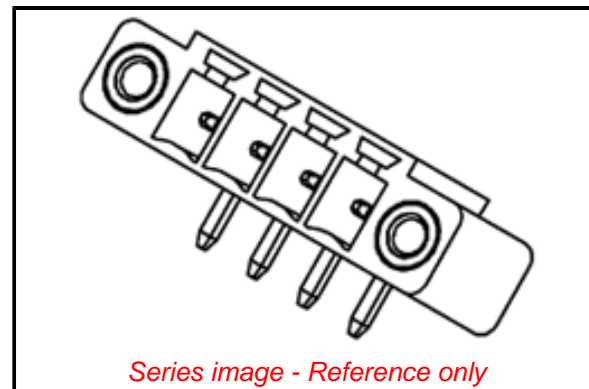

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Compliant

REACH SVHC

Contained Per -
 D(2021)4569-DC (8
 July 2021)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[39506](#) Series

Mates With

Most 3.50mm Pitch Industry Standard
 Plugs, [39504](#) Horizontal Plug with Retention
 Screws, [39507](#) Vertical Plug with Retention
 Screws

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39506-1006](#)