


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0395140002](#)
Status: **Active**
Overview: Eurostyle Terminal Blocks
Description: 3.81mm Pitch Eurostyle Horizontal Plug, with Retention Screws, 2 Circuits

Documents:

3D Model	Packaging Specification PK-39500-001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-39514-001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-39500-001-001 (PDF)	

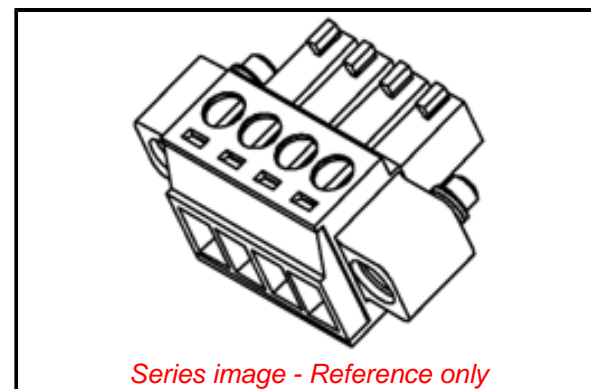

Series image - Reference only

Agency Certification

UL E48521

General

Product Family	Terminal Blocks
Series	39514
Application	N/A
Component Type	Plug
Overview	Eurostyle Terminal Blocks
Product Name	ESE, Eurostyle Pluggable
Type	Euro Block
UPC	822350688895

Physical

Circuits (Loaded)	2
Entry Angle	Vertical
Lock to Mating Part	Yes
Net Weight	1.510/g
Number of Rows	1
Orientation	Horizontal
Panel Mount	No
Pitch - Mating Interface	3.81mm
Pitch - Termination Interface	3.81mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	16, 18, 20, 22, 24
Wire Size mm ²	0.20-1.31

Electrical

Current - Maximum per Contact	8.0A
Voltage - Maximum	300V

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-39500-001-001, PK-39514-001-001
Product Specification	PS-39500-001-001
Sales Drawing	SD-39514-001-001

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - ECHA_01_2020 (16 January 2020)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[39514 Series](#)

Mates With

Most 3.81mm Pitch Industry Standard PCB Headers, [39515](#) Vertical PCB Header with Threaded Retention Inserts, [39516](#) Horizontal PCB Header with Threaded Retention Inserts

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39514-0002](#)