


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0395140010](#)
Status: **Active**
Overview: Eurostyle Terminal Blocks
Description: 3.81mm Pitch Eurostyle Horizontal Plug, with Retention Screws, 10 Circuits

Documents:

3D Model	Packaging Specification PK-39500-001-001 (PDF)
3D Model (PDF)	Packaging Specification PK-39514-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-39500-001-001 (PDF)	

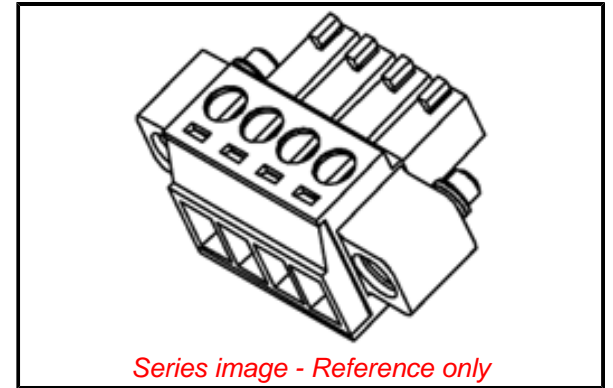

Series image - Reference only

Agency Certification

UL E48521

General

Product Family	Terminal Blocks
Series	39514
Application	N/A
Component Type	Plug
Overview	Eurostyle Terminal Blocks
Product Name	ESE, Eurostyle Pluggable
Type	Euro Block
UPC	822350688970

Physical

Circuits (Loaded)	10
Entry Angle	Vertical
Lock to Mating Part	Yes
Net Weight	7.570/g
Number of Rows	1
Orientation	Horizontal
Panel Mount	No
Pitch - Mating Interface	3.81mm
Pitch - Termination Interface	3.81mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	16, 18, 20, 22, 24
Wire Size mm ²	0.20-1.31

Electrical

Current - Maximum per Contact	8.0A
Voltage - Maximum	300V

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-39500-001-001, PK-39514-001-001
Product Specification	PS-39500-001-001
Sales Drawing	SD-39514-001-001

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[39514 Series](#)

Mates With

Most 3.81mm Pitch Industry Standard PCB Headers, [39515](#) Vertical PCB Header with Threaded Retention Inserts, [39516](#) Horizontal PCB Header with Threaded Retention Inserts

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39514-0010](#)