

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0395166003](#)
Status: **Active**
Overview: Eurostyle Terminal Blocks
Description: 3.81mm Pitch Eurostyle Horizontal PCB Header, with Threaded Retention Inserts, Green Housing, 3 Circuits

Documents:

3D Model	Product Specification PS-39500-001-001 (PDF)
3D Model (PDF)	Packaging Specification PK-39516-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

UL E48521

General

Product Family	Terminal Blocks
Series	39516
Application	N/A
Component Type	PCB Header
Overview	Eurostyle Terminal Blocks
Product Name	ESE, Eurostyle Pluggable
Type	Euro Block
UPC	822350446440

Physical

Circuits (Loaded)	3
Entry Angle	N/A
Lock to Mating Part	Yes
Number of Rows	1
Orientation	Horizontal
PC Tail Length	3.50mm
PCB Thickness - Recommended	2.50mm
Panel Mount	No
Pitch - Mating Interface	3.81mm
Pitch - Termination Interface	3.81mm
Polarized to Mating Part	Yes
Shrouded	Fully
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A


Electrical

Current - Maximum per Contact	8.0A
Voltage - Maximum	300V

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-39516-001-001
Product Specification	PS-39500-001-001
Sales Drawing	SD-39501-002-001, SD-39516-001-001

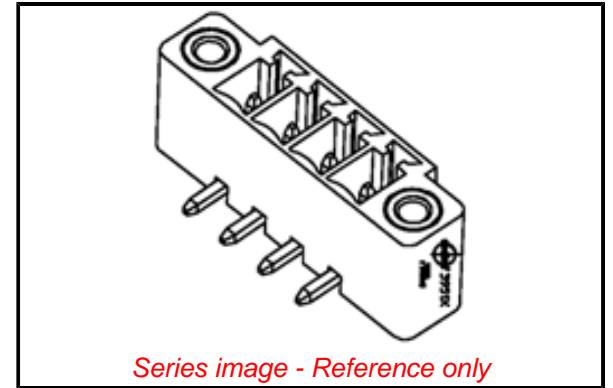

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

China RoHS
Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[39516 Series](#)

Mates With

Most 3.81mm Pitch Industry Standard Plugs,
[39517](#) Vertical Plug with Retention Screws,
[39514](#) Horizontal Plug with Retention
Screws

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39516-6003](#)