

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0398800636](#)
Status: **Active**
Overview: Eurostyle Terminal Blocks
Description: 5.08mm Pitch Beau Eurostyle Medium Profile, Two Level Terminal Block, Modular, 36 Circuits

Documents:

| | |
|--------------------------------|--|
| 3D Model | Drawing (PDF) |
| 3D Model (PDF) | RoHS Certificate of Compliance (PDF) |

General

| | |
|----------------|---|
| Product Family | Terminal Blocks |
| Series | 39880 |
| Application | N/A |
| Component Type | One Piece |
| Overview | Eurostyle Terminal Blocks |
| Product Name | Eurostyle Multi-Level |
| Type | Euro Block |
| UPC | 822350813419 |

Physical

| | |
|-------------------------------|--|
| Circuits (Loaded) | 36 |
| Entry Angle | Horizontal |
| Lock to Mating Part | None |
| Number of Rows | 2 |
| Orientation | Vertical |
| PC Tail Length | 3.80mm |
| PCB Retention | N/A |
| PCB Thickness - Recommended | 2.60mm |
| Panel Mount | No |
| Pitch - Mating Interface | 5.08mm |
| Pitch - Termination Interface | 5.08mm |
| Polarized to Mating Part | N/A |
| Shrouded | Fully |
| Stackable | Yes |
| Temperature Range - Operating | 110°C |
| Wire Size AWG | 12, 14, 16, 18, 20, 22, 24, 26, 28, 30 |
| Wire Size mm ² | 0.20-2.50 |


Electrical

| | |
|-------------------------------|-------|
| Current - Maximum per Contact | 17.5A |
| Voltage - Maximum | 300V |

Material Info

Reference - Drawing Numbers

| | |
|---------------|--------------|
| Sales Drawing | SD-39880-008 |
|---------------|--------------|

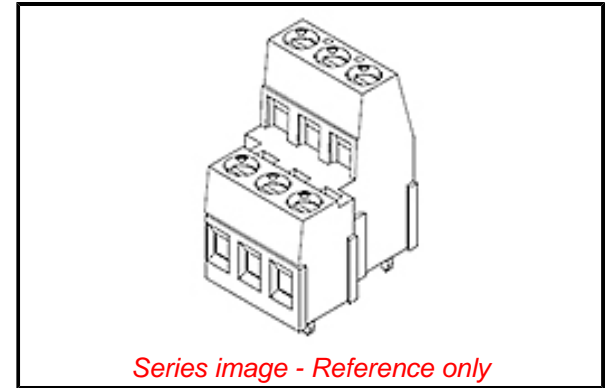

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[39880 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39880-0636](#)