

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0399400309](#)
Status: **Active**
Overview: Eurostyle Terminal Blocks
Description: 5.08mm Pitch Beau EuroMate Pluggable PCB Terminal Block, Dual Level, 270° Wire Entry, 9 Circuits

Documents:

3D Model	Product Specification PS-39940-001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Drawing (PDF)	

Agency Certification

UL E48521

General

Product Family	Terminal Blocks
Series	39940
Application	N/A
Comments	Gold plating available
Component Type	Plug
Overview	Eurostyle Terminal Blocks
Product Name	EuroMate Pluggable
Type	Euro Block
UPC	800756372440

Physical

Circuits (Loaded)	9
Color - Resin	Black
Entry Angle	Horizontal
Flammability	94V-0
Lock to Mating Part	None
Material - Resin	Nylon
Number of Rows	2
Orientation	Vertical
Panel Mount	No
Pitch - Mating Interface	5.08mm
Pitch - Termination Interface	5.08mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	130°C
Termination Interface: Style	Screw or Lug
Wire Size AWG	12, 14, 16, 18, 20, 22
Wire Size mm ²	0.50-2.50

Electrical


Current - Maximum per Contact	15.0A
Voltage - Maximum	300V

Material Info

Engineering Number 940909

Reference - Drawing Numbers

Product Specification	PS-39940-001-001
Sales Drawing	SD-39940-005

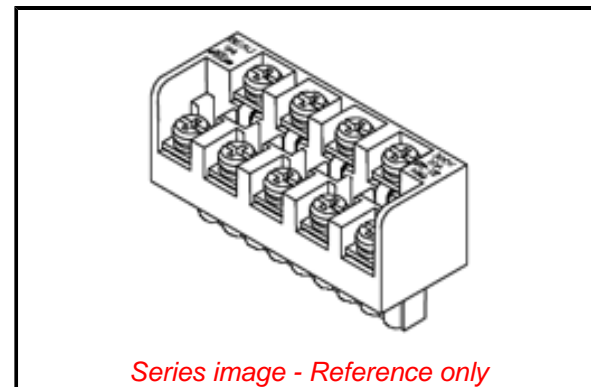

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)4578-DC (25
June 2020)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[39940](#) Series

Mates With

[395310009](#) , [395311009](#) , [395320009](#) ,
[395321009](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39940-0309](#)