

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0399400411](#)
Status: **Active**
Overview: Eurostyle Terminal Blocks
Description: 5.08mm Pitch Beau EuroMate Pluggable PCB Terminal Block, Dual Level, 90° Wire Entry, with Retention Screws, 11 Circuits

Documents:

3D Model	Product Specification PS-39940-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
3D Model (PDF)	

Agency Certification

UL E48521

General

Product Family	Terminal Blocks
Series	39940
Application	N/A
Comments	Gold plating available
Component Type	Plug
Overview	Eurostyle Terminal Blocks
Product Name	EuroMate Pluggable
Type	Euro Block
UPC	800756372945

Physical

Circuits (Loaded)	11
Color - Resin	Black
Entry Angle	Horizontal
Flammability	94V-0
Lock to Mating Part	Yes
Material - Resin	Nylon
Number of Rows	2
Orientation	Vertical
PCB Retention	N/A
Panel Mount	No
Pitch - Mating Interface	5.08mm
Pitch - Termination Interface	5.08mm
Polarized to Mating Part	Yes
Shrouded	Tri-Barrier
Stackable	No
Temperature Range - Operating	130°C
Termination Interface: Style	Screw or Lug
Wire Size AWG	12, 14, 16, 18, 20, 22
Wire Size mm ²	0.50-2.50

Electrical


Current - Maximum per Contact	15.0A
Voltage - Maximum	300V

Material Info

Engineering Number 946811

Reference - Drawing Numbers

Product Specification	PS-39940-001-001
Sales Drawing	SD-39940-002-001

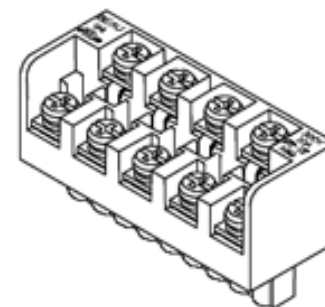

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[39940 Series](#)

Mates With

[395350011](#) , [395354011](#) , [395360011](#) , [395364011](#)

This document was generated on 07/27/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39940-0411](#)