

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0423751922](#)
Status: **Active**
Description: KK 100 Hdr Assy Bkwy 02 Ckt 30 SGold

Documents:

| | |
|--|---|
| Drawing (PDF) | Packaging Specification PK-40873-0041-001 (PDF) |
| Product Specification PS-10-07-001 (PDF) | RoHS Certificate of Compliance (PDF) |

Agency Certification

| | |
|-----|---------|
| CSA | LR19980 |
| UL | E29179 |

Application tooling part link

| | |
|-------------------------------|------------|
| Application Tooling Part Link | 11-20-1230 |
|-------------------------------|------------|

General

| | |
|----------------|-----------------------|
| Product Family | PCB Headers |
| Series | 42375 |
| Product Name | KK 254 |
| UPC | 800753813366 |

Physical

| | |
|--------------|---------|
| Flammability | 94V-0 |
| Net Weight | 0.137/g |

Electrical

| | |
|-------------------|------|
| Voltage - Maximum | 500V |
|-------------------|------|


Solder Process Data

| | |
|--|------|
| Duration at Max. Process Temperature (seconds) | 005 |
| Lead-freeProcess Capability | WAVE |
| Max. Cycles at Max. Process Temperature | 001 |
| Process Temperature max. C | 235 |

Material Info

Reference - Drawing Numbers

| | |
|-------------------------|-------------------|
| Packaging Specification | PK-40873-0041-001 |
| Product Specification | PS-10-07-001 |
| Sales Drawing | SD-42375-001-001 |

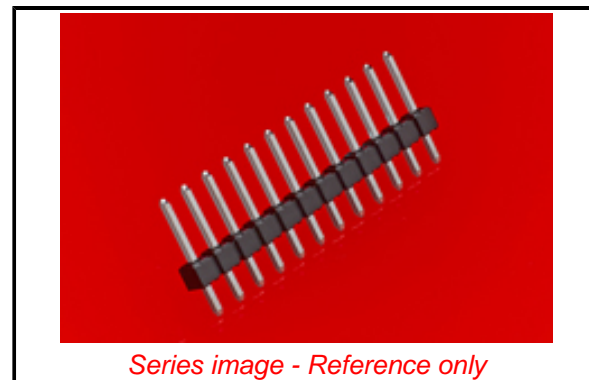

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[42375](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[42375-1922](#)