

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0423752488](#)
Status: **Active**
Description: KK 100 Hdr Assy Bkwy 04 Ckt 15 SGold

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-40873-0041-001 \(PDF\)](#)
[Product Specification PS-10-07-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

Application tooling part link

Application Tooling Part Link 11-20-1230

General

Product Family PCB Headers
 Series [42375](#)
 Product Name KK 254
 UPC 822348366897

Physical

Flammability 94V-0
 Net Weight 0.252/g

Electrical

Voltage - Maximum 500V


Solder Process Data

Duration at Max. Process Temperature (seconds) 005
 Lead-freeProcess Capability WAVE
 Max. Cycles at Max. Process Temperature 001
 Process Temperature max. C 235

Material Info

Reference - Drawing Numbers

Packaging Specification PK-40873-0041-001
 Product Specification PS-10-07-001
 Sales Drawing SD-42375-001-001

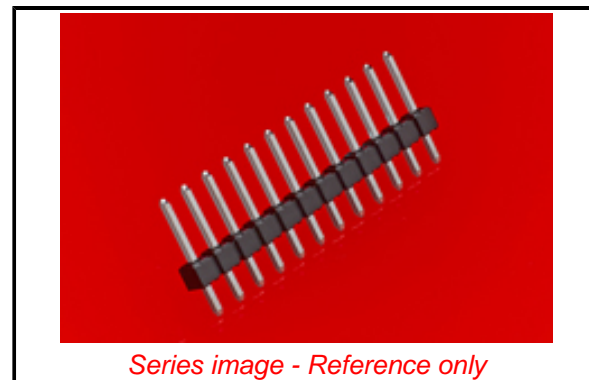

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2021)4569-DC (8
 July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[42375 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[42375-2488](#)