

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0525592834](#)  
**Status:** **Active**  
**Overview:** Easy-On FFC FPC Connectors  
**Description:** Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 28 Circuits, Tin-Silver-Bismuth Plating

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Packaging Specification SPK-52559-004-001 (PDF)</a>
<a href="#">3D Model</a>	<a href="#">Datasheet (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Product Guide (PDF)</a>
<a href="#">Product Specification PS-52559-019-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Application Specification 525590003-A00 (PDF)</a>	<a href="#">Reference Guide (PDF)</a>

**Agency Certification**

UL E29179

**General**

Product Family	FFC/FPC Connectors
Series	52559
Overview	<a href="#">Easy-On FFC FPC Connectors</a>
Product Name	Easy-On
Series Name	Slider
UPC	887191347394

**Physical**


Actuator Type	Slider
Circuits (Loaded)	28
Color - Resin	Natural
Contact Position	N/A
Durability (mating cycles max)	20
Flammability	94V-0
Mated Height	3.90mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin-Silver-Bismuth
Material - Plating Termination	Tin-Silver-Bismuth
Material - Resin	Nylon
Net Weight	352.370/mg
Number of Rows	1
Orientation	Vertical
PC Tail Length	2.00mm
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Pitch - Termination Interface	0.50mm
Polarized to PCB	No
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FFC/FPC

**Electrical**

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V

**Material Info**

**Reference - Drawing Numbers**

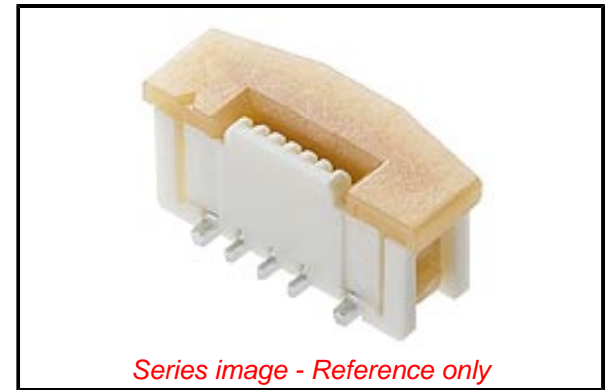

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2020)9139-DC (19  
Jan 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[52559 Series](#)

**Mates With**

Premo-Flex FFC Cable [15166](#) , [98266](#) ,  
[15266](#) , [15366](#)

Application Specification  
Packaging Specification  
Product Specification  
Sales Drawing

525590003-A00  
SPK-52559-004-001  
PS-52559-019-001  
SD-52559-059-001

This document was generated on 07/06/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[52559-2834](#)