

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0536251874](#)  
**Status:** **Active**  
**Overview:** SlimStack Board-to-Board/Board-to-FPC Connectors  
**Description:** SlimStack Board-to-Board Connector, 0.635mm Pitch, 0.635 Series, Plug, 7.00 or 13.00mm Mated Height, 6.40mm Mated Width, 180 Circuits

**Documents:**

<a href="#">3D Model</a>	<a href="#">Datasheet (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Product Guide (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification 527600000-000 (PDF)</a>	<a href="#">Reference Guide (PDF)</a>
<a href="#">Packaging Specification SPK-53625-001-001 (PDF)</a>	

**General**


Product Family	PCB Headers
Series	<a href="#">53625</a>
Application	Board-to-Board, Signal
Comments	Stacking-Type
Overview	<a href="#">SlimStack Board-to-Board/Board-to-FPC Connectors</a>
Product Name	SlimStack
Series Name	0.635, Rigid
UPC	191128871273

**Physical**

Breakaway	No
Circuits (Loaded)	180
Circuits (maximum)	180
Color - Resin	Brown
Durability (mating cycles max)	50
First Mate / Last Break	No
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	None
Mated Height	13.00mm, 7.00mm
Mated Width	6.40mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	1671.000/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	Yes
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.635mm
Plating min - Mating	0.254µm
Plating min - Termination	1.016µm
Polarized to PCB	Yes
Robotic Placement	Metal Cap
Shrouded	Fully
Temperature Range - Operating	-55° to +105°C
Termination Interface: Style	Surface Mount

**Electrical**

Current - Maximum per Contact	0.5A
-------------------------------	------

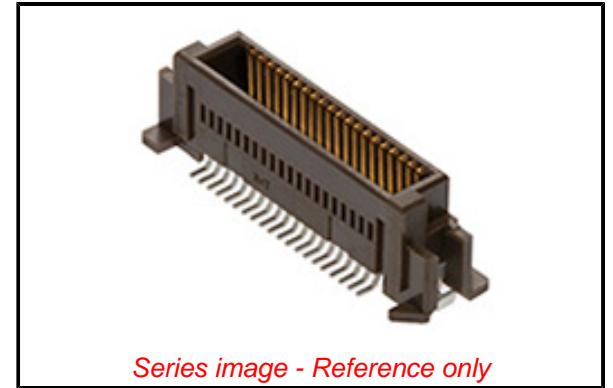

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[53625](#) Series

**Mates With**

SlimStack 0.635 Receptacle [52885](#) , [52901](#)

Voltage - Maximum

100V

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification

SPK-53625-001-001

Product Specification

527600000-000

Sales Drawing

SD-53625-002-001, SD-53625-003-001

This document was generated on 10/07/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[53625-1874](#)