

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0587230010](#)
Status: **Active**
Overview: HMC Heavy Duty Rectangular Connectors
Description: HMC Rectangular Industrial Hood, Multi-Module Type, Vertical, External Thread, 48-72 Circuits

Documents:

3D Model	Product Specification PS-58719-006-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
3D Model (PDF)	

General

Product Family	I/O Connectors
Series	58723
Application	Panel-Mount
Component Type	Hood
Overview	HMC Heavy Duty Rectangular Connectors
Product Name	HMC
Type	N/A
UPC	800753921153

Physical

Circuits (Loaded)	48
Circuits (maximum)	48
Durability (mating cycles max)	50
Lock to Mating Part	Yes
Material - Plating Mating	N/A
Net Weight	348271.700/mg
Orientation	Vertical
Packaging Type	Bag
Panel Mount	N/A
Pitch - Mating Interface	N/A
Polarized to Mating Part	Yes
Temperature Range - Operating	-55° to +125°C
Termination Interface: Style	N/A
Waterproof / Dustproof	Yes
Waterproof / Dustproof Type	IP65


Electrical

Current - Maximum per Contact	13.0A, 20.0A
Voltage - Maximum	250V AC

Material Info

Reference - Drawing Numbers

Product Specification	PS-58719-006-001
Sales Drawing	SD-58723-002-001

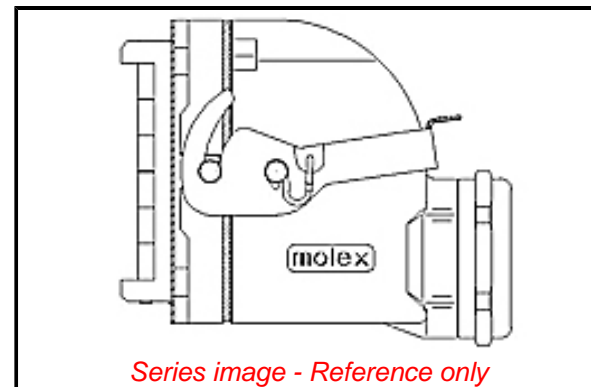

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(a)-I,6(b)-II

REACH SVHC

Contained Per - D(2021)4569-DC (8 July 2021)
Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

China RoHS

ELV

50 Image

RoHS Phthalates

Not Relevant

Not Contained

Search Parts in this Series

[58723 Series](#)

Mates With

[587190010](#) Panel Mount Bracket Type A Polarization, [587190020](#) PanelMount Bracket Type B Polarization

Use With

[58866](#) End Bell Cap Assembly, [58721](#) Hood Bracket

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[58723-0010](#)