

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0588660002**

Status: **Active**

Overview: HMC Heavy Duty Rectangular Connectors

Description: HMC Rectangular Industrial End Bell Cap Assembly, PG36, 14.00-18.00mm dia. Wire Size, Blue Bush, for External Threaded Hoods

Documents:

[3D Model](#)

[Drawing \(PDF\)](#)

[3D Model \(PDF\)](#)

[Product Specification PS-58719-006-001 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	I/O Connectors
Series	<u>58866</u>
Application	Panel-Mount
Component Type	Bell Cap Assembly
Overview	<u>HMC Heavy Duty Rectangular Connectors</u>
Product Name	HMC
Type	N/A
UPC	800756018140

Physical

Circuits (Loaded)	48, 72
Color - Resin	Blue
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	N/A
Material - Resin	PVC
Net Weight	156.000/g
Orientation	Vertical
Packaging Type	Bag
Panel Mount	N/A
Pitch - Mating Interface	N/A
Polarized to Mating Part	Yes
Termination Interface: Style	N/A
Waterproof / Dustproof	Yes
Waterproof / Dustproof Type	IP65


Electrical

Current - Maximum per Contact	N/A
-------------------------------	-----

Material Info

Reference - Drawing Numbers

Product Specification	PS-58719-006-001
Sales Drawing	SD-58866-002-001

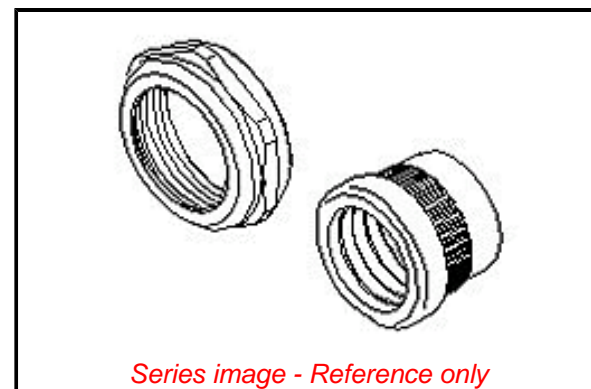

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

50 Image

Not Relevant

Contained: hala

Search Parts in this Series

58866 Series

Use With

587230010 Hood

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[58866-0002](#)