

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0638112400](#)  
**Status:** **Active**  
**Overview:** [Application Tooling](#)  
**Description:** PremiumGrade Hand Crimp Tool for 1.50mm MX150 Blade Male Terminals, 14-16 AWG

**Documents:**  
[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Application Tooling
Series	<a href="#">207129</a>
Comments	Prototype and field repair. Type: 4A
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	<a href="mailto:applicationtooling@molex.com">applicationtooling@molex.com</a>
Overview	<a href="#">Application Tooling</a>
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	756054649671
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.


**Physical**

Net Weight 428.885/zg

**Material Info**

**Reference - Drawing Numbers**

Application Tooling Documents  
 ATS-6381124HM-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001

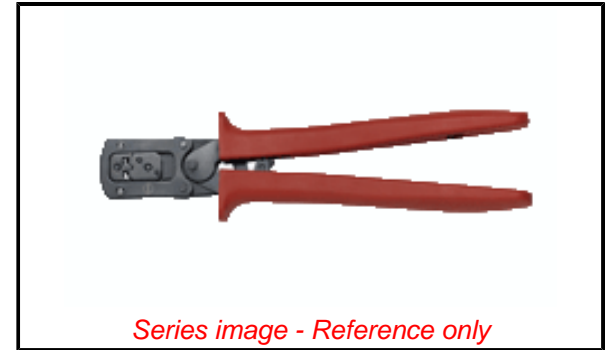

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/61/2018 (27 June 2018)

**Halogen-Free**

**Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Not Relevant

Not Relevant

Not Contained

**Search Parts in this Series**

[207129](#) Series

**Use With**

Loose Piece Terminals

**Application Tooling**

**Description**

**FAQ**

**Product #**

MX150 Male [330000001](#)

Terminal for Mat-Sealed or Unsealed Connectors, Tin Plating, 14 AWG, Right Reel Payoff

MX150 Male [330000002](#)

Terminal for Mat-Sealed or Unsealed Connectors, Tin Plating, 16, 18 and 20 AWG, Right Reel Payoff

MX150 Male [330001001](#)

Terminal for Mat-Sealed or Unsealed Connectors, Tin

Plating, 14 AWG, Left Reel Payoff MX150 Male	<u>330001002</u>
Terminal for Mat- Sealed or Unsealed Connectors, Tin Plating, 16, 18 and 20 AWG, Left Reel Payoff MX150 Male	<u>330110002</u>
Terminal for Mat- Sealed or Unsealed Connectors, Gold Plating, 14 AWG, Left Reel Payoff MX150 Male	<u>330110004</u>
Terminal for Mat- Sealed or Unsealed Connectors, Gold Plating, 16, 18 and 20 AWG, Left Reel Payoff MX150 Male	<u>330111002</u>
Terminal for Mat- Sealed or Unsealed Connectors, Gold Plating, 14 AWG, Right Reel Payoff MX150 Male	<u>330111004</u>
Terminal for Mat- Sealed or Unsealed Connectors, Gold Plating, 16, 18 and 20 AWG, Right Reel Payoff MX150 Male	<u>330112002</u>
Terminal for Mat- Sealed or Unsealed Connectors, Silver Plating, 16, 18 and 20 AWG, Right Reel Payoff MX150 Male	<u>330112003</u>
Terminal for Mat- Sealed or Unsealed Connectors, Silver Plating, 14 AWG, Right Reel Payoff MX150 Male	<u>330113002</u>
Terminal for Mat- Sealed or Unsealed Connectors, Silver Plating, 16, 18 and 20 AWG, Left Reel Payoff MX150 Male	<u>330113003</u>
Terminal for Mat- Sealed or Unsealed Connectors, Silver Plating, 14 AWG, Left Reel Payoff	

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63811-2400](#)