

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0638130600](#)  
**Status:** **Active**  
**Overview:** [Application Tooling](#)  
**Description:** Manual Activation and Deactivation Tool

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**General**


Product Family	Application Tooling
Series	<a href="#">207122</a>
Function	Activation, Deactivation
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	<a href="mailto:applicationtooling@molex.com">applicationtooling@molex.com</a>
Overview	<a href="#">Application Tooling</a>
Product Name	N/A
Tool Type	N/A
UPC	800753891920
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

**Material Info**

**Reference - Drawing Numbers**

Application Tooling Documents

ATS-638130600-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001

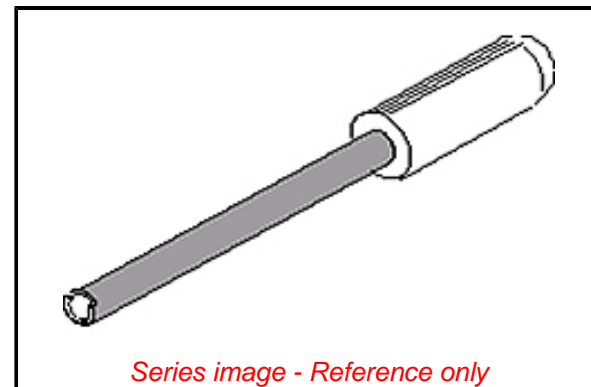

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[207122 Series](#)

**Application Tooling** | **FAQ**  
**Description** | **Product #**

Sabre Crimp Terminal, Male, 18 AWG, 3.30mm Max. Insulation Diameter, Reel Packaged, Tin (Sn) Plated Brass Contact	<a href="#">431781002</a>
Sabre Crimp Terminal, Male, 14-16 AWG or double 18-20 AWG, 4.57mm Max. Insulation Diameter, Reel Packaged, Tin (Sn) Plated Brass Contact	<a href="#">431782002</a>
Sabre Crimp Terminal, Male, 18-20 AWG, 3.30mm max. Insulation Diameter, Reel	<a href="#">431784002</a>

Packaged, Tin (Sn)  
Plated Brass Contact  
Sabre Crimp 431785002  
Terminal, Male, 18  
AWG, 3.30mm Max.  
Insulation Diameter,  
Reel Packaged,  
Tin (Sn) Plated  
Brass Contact, Last-  
Make Wipe Length,  
complies with the  
UL1977 finger proof  
access requirement  
Sabre Crimp 431786002  
Terminal, Male,  
14-18 AWG, 4.57mm  
Insulation Diameter,  
Reel Packaged,  
Tin (Sn) Plated  
Brass Contact, Last-  
Make Wipe Length,  
complies with the  
UL1977 finger proof  
access requirement

This document was generated on 10/07/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63813-0600](#)