

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0638233270](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: Modular Crimp Head for the Battery 638160200 and Air 638160100 Tools
Replacement Part Number : <http://www.molex.com/molex/search/partSearch?pQuery=&sType=p&query=0638233200638233200>


Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Application Tooling
Series	207129
Comments	See Tooling Specification (PDF) Above. Modular Crimp Heads are not sold separately; the complete hand tool needs to be ordered to obtain a Modular Crimp Head 638233200 . Type: TOOL KIT
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	PremiumGrade
Replacement Part Number	638233200
Tool Type	Hand Crimp Tool
UPC	884982366480
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers
Application Tooling Documents [ATS-6382332HM-001](#)

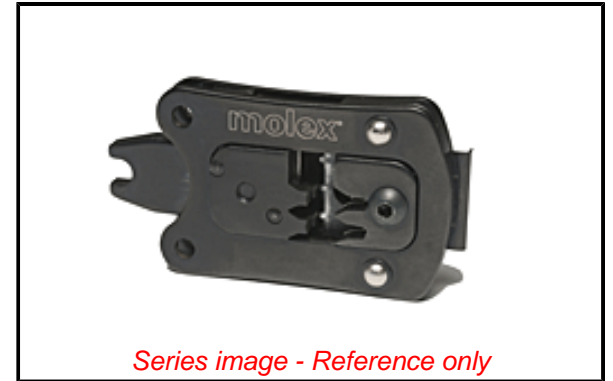

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[207129](#) Series

Application Tooling | **FAQ**

Description | **Product #**

Sabre Crimp [431782001](#)

Terminal, Male, Double 20 AWG, 4.57mm Max.

Insulation Diameter, Reel Packaged, Unplated, Brass Contact

Sabre Crimp [431782002](#)

Terminal, Male, 14-16 AWG or double 18-20 AWG, 4.57mm Max.

Insulation Diameter, Reel Packaged, Tin (Sn) Plated Brass Contact

Sabre Crimp [431786002](#)

Terminal, Male, 14-18 AWG, 4.57mm

Insulation Diameter,
Reel Packaged,
Tin (Sn) Plated
Brass Contact, Last-
Make Wipe Length,
complies with the
UL1977 finger proof
access requirement

This document was generated on 07/29/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63823-3270](#)