

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0638618100](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: [FineAdjust Applicator](#)

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)


General

Product Family	Application Tooling
Series	207127
Comments	See Tooling Specification (PDF) Above, Terminals will accommodate the UL1007 wires
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	FineAdjust
Tool Type	Applicator
UPC	822350861106
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers
[Application Tooling Documents](#)

ATS-638618100-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001, TM-638004900-001, TM-638004900CN-001, TM-638004900SP-001

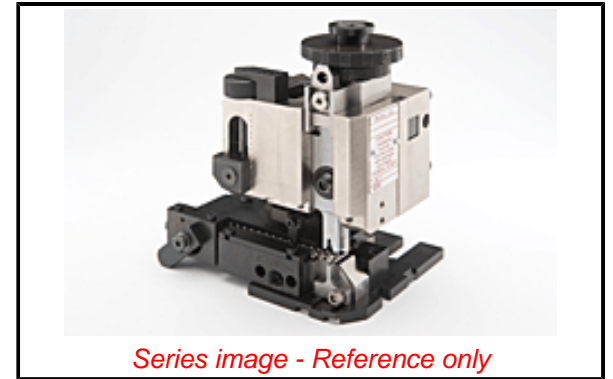

EU ELV
Not Reviewed

EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free Status	
Not Reviewed	

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[207127 Series](#)

Use With
Molex TM-3000: [638017200](#) , [638017300](#) , Molex TM-4000: [638017600](#) , Molex TM-2000: [638008300](#) , [638008400](#) , and Most Industry Standard Presses or Wire Process Machines

Application Tooling Description	FAQ Product #
2.00mm Pitch, iGrid Female Crimp Terminal, Female, Tin (Sn) Plating, 26-28 AWG, Reel	5016481000
2.00mm Pitch, iGrid Female Crimp Terminal, 0.10µm Gold (Au) Plating, 26-26 AWG, Reel	5030952200
2.00mm Pitch, iGrid Female Crimp Terminal, 0.38µm Gold (Au) Plating, 26-26 AWG, Reel	5030953200

2.00mm Pitch, 5030954200
iGrid Female Crimp
Terminal, 0.76µm
Gold (Au) Plating,
26-26 AWG, Reel

This document was generated on 07/30/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63861-8100](#)