

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0638850400](#)  
**Status:** **Active**  
**Overview:** [Application Tooling](#)  
**Description:** [Mini-Mac Applicator](#)

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**General**


Product Family	Application Tooling
Series	<a href="#">207127</a>
Comments	The Molex Tape Applicator requires an industry standard crimp press with a 4way air like the Molex TM-3000: <a href="#">638017200</a> , <a href="#">638017300</a> , and the Molex TM-4000: <a href="#">638017600</a>
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	<a href="mailto:applicationtooling@molex.com">applicationtooling@molex.com</a>
Overview	<a href="#">Application Tooling</a>
Product Name	Mini-Mac
Tool Type	Applicator
UPC	822348748983
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

**Material Info**

**Reference - Drawing Numbers**

Application Tooling Documents

638850400-001, TM-638800000-001, TM-638800000SP-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

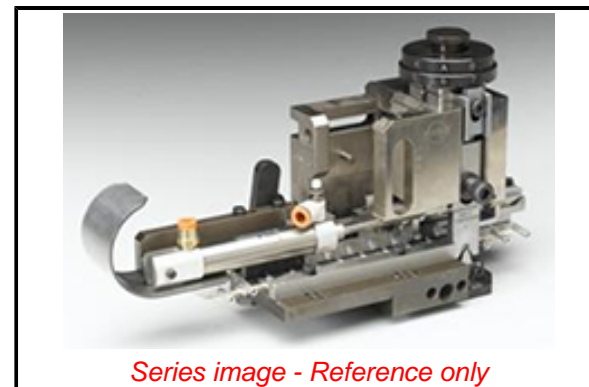

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Relevant**

**REACH SVHC**

Not Relevant

**Halogen-Free**

**Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Relevant

**Search Parts in this Series**

[207127 Series](#)

**Use With**

Molex TM-3000: [638017200](#) , [638017300](#) , Molex TM-4000: [638017600](#) , and Most Industry Standard Presses or Wire Process Machines

**Application Tooling**

**Description**

**FAQ**

**Product #**

Application Tooling Description	FAQ Product #
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<a href="#">190700061</a>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<a href="#">190700064</a>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<a href="#">190700066</a>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<a href="#">190700070</a>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<a href="#">190700072</a>

InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire, Tape	<u>190700076</u>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<u>190700079</u>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<u>190700084</u>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<u>190700087</u>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<u>190700092</u>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<u>190700100</u>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<u>190700104</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 3/8" (M9), Length 31.12mm, Mylar Tape Carrier	<u>190730060</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 5/16" (M8), Length 31.12mm, Mylar Tape Carrier	<u>190730062</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 4 (M2.6), Length 20.32mm, Mylar Tape Carrier	<u>190730066</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 6 (M3.5), Length 20.32mm, Mylar Tape Carrier	<u>190730070</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 8 (M4), Length 20.32mm, Mylar Tape Carrier	<u>190730073</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 1/4" (M6), Length 27.36mm, Mylar Tape Carrier	<u>190730077</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 5/16" (M8), Length 27.36mm, Mylar Tape Carrier	<u>190730080</u>

Avikrimp Ring	<u>190730084</u>
Tongue Terminal for 14 to 16 AWG Wire, Stud Size 6 (M3.5), Length 22.48mm, Mylar Tape Carrier	
Avikrimp Ring	<u>190730086</u>
Tongue Terminal for 14 to 16 AWG Wire, Stud Size 8 (M4), Length 22.48mm, Mylar Tape Carrier	
Avikrimp Ring	<u>190730088</u>
Tongue Terminal for 14 to 16 AWG Wire, Stud Size 10 (M5), Length 22.48mm, Mylar Tape Carrier	
Avikrimp Ring	<u>190730096</u>
Tongue Terminal for 14 to 16 AWG Wire, Stud Size 8 (M4), Length 23.77mm, Mylar Tape Carrier	
Avikrimp Ring	<u>190730099</u>
Tongue Terminal for 14 to 16 AWG Wire, Stud Size 10 (M5), Length 23.77mm, Mylar Tape Carrier	
InsulKrimp Snap	<u>190990026</u>
Spade for 16-14 AWG Wire, Stud Size 5 (M3), Mylar Tape Carrier, Blue	
InsulKrimp Snap	<u>190990028</u>
Spade for 16-14 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier, Blue	
InsulKrimp Snap	<u>190990033</u>
Spade for 16-14 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier, Length 22.12mm, Blue	
InsulKrimp Snap	<u>190990035</u>
Spade for 16-14 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier, Length 23.34mm, Blue	
Avikrimp Snap	<u>191150025</u>
Spade Terminal for 14-16 AWG Wire	
Avikrimp Snap	<u>191150030</u>
Spade Terminal for 14-16 AWG Wire	
InsulKrimp Flanged	<u>191210027</u>
Spade Tongue Terminal for 14-16 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier	

InsulKrimp Flanged Spade Tongue Terminal for 14-16 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier	<u>191210029</u>
InsulKrimp Flanged Spade Tongue Terminal for 14-16 AWG Wire, Stud Size 10 (M5), Length 20.19mm, Mylar Tape Carrier	<u>191210031</u>
Avikrimp Flanged Spade Tongue Terminal for 14-16 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier	<u>191270041</u>
Avikrimp Flanged Spade Tongue Terminal for 14-16 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier	<u>191270044</u>
BLOCK SPADE AVIKRIMP TAPED (BB-8781-06T)	<u>191390043</u>
InsulKrimp Spade Tongue Terminal for 14-16 AWG Wire, Tape and Reel	<u>191440027</u>
Avikrimp Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier, Length 20.45mm	<u>191980013</u>
Avikrimp Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier, Length 20.42mm	<u>191980018</u>
Avikrimp Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier	<u>191980020</u>
Avikrimp Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier	<u>191980026</u>
Avikrimp Wire Pin Terminal for 16-14 AWG Wire, Mylar Tape Carrier	<u>192130012</u>

This document was generated on 07/27/2021

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63885-0400](#)