

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0638850900](#)  
**Status:** **Active**  
**Overview:** [Application Tooling](#)  
**Description:** [Mini-Mac Applicator](#)

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**General**


|                                |   |
|--------------------------------|---|
| Product Family                 | Application Tooling   |
| Series                         | <a href="#">207127</a>  |
| Comments                       | The Molex Tape Applicator requires an industry standard crimp press with a 4way air like the Molex TM-3000: <a href="#">638017200</a> , <a href="#">638017300</a> , and the Molex TM-4000: <a href="#">638017600</a>  |
| Function                       | Crimp   |
| Geographic Area                | Global  |
| Level of Automation            | Automatic, Semi-Automatic   |
| More Detailed Tech Information | <a href="mailto:applicationtooling@molex.com">applicationtooling@molex.com</a>  |
| Overview                       | <a href="#">Application Tooling</a>   |
| Product Name                   | Mini-Mac  |
| Tool Type                      | Applicator  |
| UPC                            | 822348758579  |
| Warranty Disclaimer            | CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified. |

**Material Info**

**Reference - Drawing Numbers**

Application Tooling Documents

ATS-638850900-001, TM-638800000-001, TM-638800000SP-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

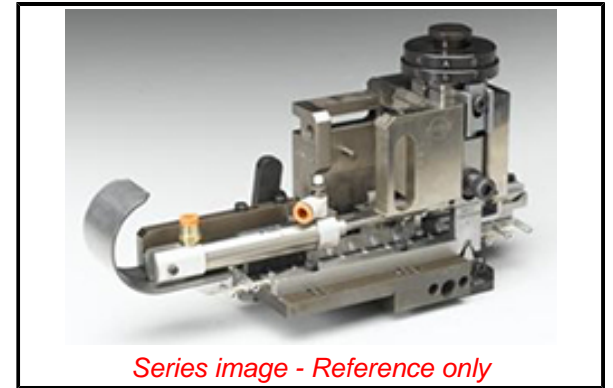

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[207127 Series](#)

**Use With**

Molex TM-3000: [638017200](#) , [638017300](#) , Molex TM-4000: [638017600](#) , and Most Industry Standard Presses or Wire Process Machines

**Application Tooling**

**FAQ**

**Description**

**Product #**

Avikrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm<sup>2</sup>) Wire, Mylar Tape, Tab 2.79 x 0.51mm [190190024](#)

Avikrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm<sup>2</sup>) Wire, Mylar Tape, Tab 2.79 x 0.81mm [190190026](#)

Avikrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm<sup>2</sup>) Wire, [190190030](#)

Avikrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm<sup>2</sup>) Wire,

Mylar Tape, Tab 4.75  
x 0.51mm  
Avikrimp Quick 190190033  
Disconnect,  
Female, for 14-16  
(2.00-1.30mm<sup>2</sup>) Wire,  
Mylar Tape, Tab 6.35  
x 0.81mm  
Avikrimp Quick 190190063  
Disconnect,  
Female, for 14-16  
(2.00-1.30mm<sup>2</sup>) Wire,  
Mylar Tape, Tab 5.21  
x 0.81mm  
Avikrimp Quick 190190064  
Disconnect,  
Female, for 14-16  
(2.00-1.30mm<sup>2</sup>) Wire,  
Mylar Tape, Tab 5.21  
x 0.51mm  
InsulKrimp Quick 190230004  
Disconnect,  
Male, for 18-22  
(0.80-0.35mm<sup>2</sup>) Wire,  
Mylar Tape, Tab 4.75  
x 0.51mm  
Quixon Quick 192750006  
Disconnect, Avikrimp  
Style, Female,  
Partially Insulated  
Blue, 14-16 AWG,  
Mylar Tap

This document was generated on 07/27/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63885-0900](#)