

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0638851000](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: [Mini-Mac Applicator](#)

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Application Tooling
Series	207127
Comments	The Molex Tape Applicator requires an industry standard crimp press with a 4way air like the Molex TM-3000: 638017200 , 638017300 , and the Molex TM-4000: 638017600
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	Mini-Mac
Tool Type	Applicator
UPC	822348758593
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Physical


Net Weight 6214.215/kg

Material Info

Reference - Drawing Numbers

Application Tooling Documents

ATS-638851000-001, TM-638800000-001, TM-638800000SP-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

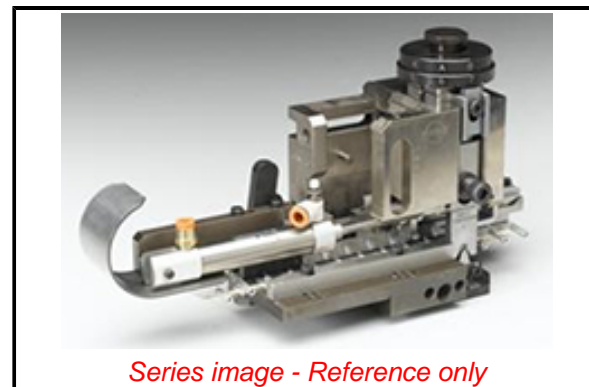

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[207127 Series](#)

Use With

Molex TM-3000: [638017200](#) , [638017300](#) , Molex TM-4000: [638017600](#) , and Most Industry Standard Presses or Wire Process Machines

Application Tooling | **FAQ**

Description	Product #
Krimptite Ring Tongue Terminal for 14-16 Heavy Duty AWG Wire	190440164
Krimptite Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 4 (M2.6), Length 19.94mm, Mylar Tape Carrier	190690147
Krimptite Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 8 (M4), Length 19.94mm, Mylar Tape Carrier	190690208

Krimptite Ring	<u>190690212</u>
Tongue Terminal for 10-12 AWG Wire, Stud Size 10 (M5), Length 19.94mm, Mylar Tape Carrier	
Krimptite Ring	<u>190690218</u>
Tongue Terminal for 10-12 AWG Wire, Stud Size 10 (M5), Length 24.18mm, Mylar Tape Carrier	
Krimptite Ring	<u>190690221</u>
Tongue Terminal for 10-12 AWG Wire, Stud Size 1/4" (M6), Length 24.18mm, Mylar Tape Carrier	
Krimptite Ring	<u>190690225</u>
Tongue Terminal for 10-12 AWG Wire, Stud Size 5/16" (M8), Length 24.18mm, Mylar Tape Carrier	
Krimptite Ring	<u>190690232</u>
Tongue Terminal for 10-12 AWG Wire, Stud Size 6 (M3.5), Length 18.82mm, Mylar Tape Carrier	
Krimptite Ring	<u>190690235</u>
Tongue Terminal for 10-12 AWG Wire, Stud Size 8 (M4), Length 18.82mm, Mylar Tape Carrier	
Krimptite Ring	<u>190690243</u>
Tongue Terminal for 10-12 AWG Wire, Stud Size 3/8" (M9), Length 26.82mm, Mylar Tape Carrier	
Krimptite Ring	<u>190690246</u>
Tongue Terminal for 10-12 AWG Wire, Stud Size 5/16" (M8), Length 26.82mm, Mylar Tape Carrier	
MULTI-STUD	<u>190790012</u>
KRIMPTITE TAPED (C-1006-MST)	
Krimptite Snap	<u>190980070</u>
Spade Terminal, for 10-12 AWG Wire, Stud Size 5 (M3), 16.87mm Length	
Krimptite Snap	<u>190980091</u>
Spade Terminal, for 10-12 AWG Wire, Stud Size 10 (M5), 19.60mm Length	
Krimptite Flanged	<u>191180081</u>
Spade Tongue Terminal for 10-12 AWG Wire, Stud	

Size 8 (M4), Length
 19.91mm, Mylar
 Tape Carrier
 Krimptite Flanged 191180083
 Spade Tongue
 Terminal for 10-12
 AWG Wire, Stud
 Size 10 (M5), Length
 19.91mm, Mylar
 Tape Carrier
 Krimptite Flanged 191180087
 Spade Tongue
 Terminal for 10-12
 AWG Wire, Stud
 Size 8 (M4), Length
 19.56mm, Mylar
 Tape Carrier
 Krimptite Flanged 191180090
 Spade Tongue
 Terminal for 10-12
 AWG Wire, Stud
 Size 10 (M5), Length
 19.56mm, Mylar
 Tape Carrier
 Krimptite Butt Splice 191890017
 for 10-12 AWG Wire
 VersaKrimp Ring 191930111
 Tongue Terminal for
 10-12 AWG Wire,
 Tape and Reel
 VersaKrimp Ring 191930113
 Tongue Terminal for
 10-12 AWG Wire,
 Stud Size 10 (M5),
 5.31mm, Mylar Tape
 Carrier
 RING VERSAKRIMP 191930118
 TAPED (C-330-14T)
 Krimptite Temp- 192030092
 Term Ring Tongue
 Terminal for 10 to
 12 AWG Wire, Stud
 Size 6 (M3.5), Mylar
 Tape Carrier
 Krimptite Temp- 192030094
 Term Ring Tongue
 Terminal for 10 to
 12 AWG Wire, Stud
 Size 10 (M5), Mylar
 Tape Carrier
 Krimptite Temp- 192030095
 Term Ring Tongue
 Terminal for 10 to
 12 AWG Wire, Stud
 Size 1/4" (M6), Mylar
 Tape Carrier
 VersaKrimp Temp- 192030098
 Term Ring Tongue
 Terminal for 10 to
 12 AWG, Stud Size
 8 (M4), Mylar Tape
 Carrier
 VersaKrimp Temp- 192030100
 Term Ring Tongue
 Terminal for 10 to

12 AWG Wire, Stud
Size 10 (M5), Mylar
Tape Carrier
VersaKrimp Temp- 192030101
Term Ring Tongue
Terminal for 10 to
12 AWG Wire, Stud
Size 1/4" (M6), Mylar
Tape Carrier
Krimptite Temp- 192030114
Term Ring Tongue
Terminal for 10 to
12 AWG Wire, Stud
Size 10 (M5), Mylar
Tape Carrier
Krimptite Wire Pin 192110002
Terminal for 12-10
AWG Wire, Mylar
Tape Carrier
Step Down Butt 192150027
Splice for 10-16
AWG Wire, Tape and
Reel
VersaKrimp Butt 192150030
Splice for 10-12
AWG Wire, Tape and
Reel

This document was generated on 07/26/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63885-1000](#)