

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0638851500](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: Mini-Mac Pneumatic Applicator for Industrial Terminals 6-26 AWG

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Application Tooling
Series	207127
Comments	The Molex Tape Applicator requires an industry standard crimp press with a 4way air like the Molex TM-3000: 638017200 , 638017300 , and the Molex TM-4000: 638017600
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	Mini-Mac
Tool Type	Applicator
UPC	822348758654
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Physical


Net Weight 4910.000/g

Material Info

Reference - Drawing Numbers

Application Tooling Documents

ATS-638851500-001, TM-638800000-001, TM-638800000SP-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

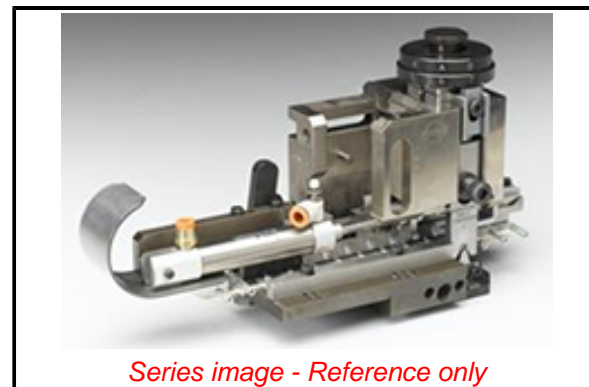

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Relevant

REACH SVHC

Not Relevant

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Relevant

Search Parts in this Series

[207127 Series](#)

Use With

Molex TM-3000: [638017200](#) , [638017300](#) , Molex TM-4000: [638017600](#) , and Most Industry Standard Presses or Wire Process Machines

Application Tooling

FAQ

Description	Product #
Avikrimp Quick Disconnect, Male, for 10-12 (5.00-3.30mm ²) Wire, Mylar Tape, Tab 6.35 x 0.81mm	190250006
InsulKrimp Ring Tongue Terminal for 14-16 AWG	190540093
InsulKrimp Ring Tongue Terminal for Heavy Duty 14-16 AWG Wire	190540099
InsulKrimp Ring Tongue Terminal for	190540127

14-16 Heavy Duty
AWG Wire

InsulKrimp Ring [190700120](#)

Tongue Terminal for
10-12 AWG Wire,
Stud Size 6 (M3.5),
Length 27.33mm,
Mylar Tape Carrier

InsulKrimp Ring [190700122](#)

Tongue Terminal for
10-12 AWG Wire,
Stud Size 8 (M4),
Length 27.33mm,
Mylar Tape Carrier

InsulKrimp Ring [190700125](#)

Tongue Terminal for
10-12 AWG Wire,
Stud Size 10 (M5),
Length 27.33mm,
Mylar Tape Carrier

InsulKrimp Ring [190700131](#)

Tongue Terminal for
10-12 AWG Wire,
Stud Size 10 (M5),
Length 31.60mm,
Mylar Tape Carrier

InsulKrimp Ring [190700133](#)

Tongue Terminal for
10-12 AWG Wire,
Stud Size 1/4" (M6),
Length 31.60mm,
Mylar Tape Carrier

InsulKrimp Ring [190700137](#)

Tongue Terminal for
10-12 AWG Wire,
Stud Size 5/16" (M8),
Length 31.60mm,
Mylar Tape Carrier

InsulKrimp Ring [190700144](#)

Tongue Terminal for
10-12 AWG Wire,
Stud Size 6 (M3.5),
Length 26.21mm,
Mylar Tape Carrier

InsulKrimp Ring [190700146](#)

Tongue Terminal for
10-12 AWG Wire,
Stud Size 8 (M4),
Length 26.21mm,
Mylar Tape Carrier

InsulKrimp Ring [190700151](#)

Tongue Terminal for
10-12 AWG Wire,
Stud Size 1/4" (M6),
Length 34.21mm,
Mylar Tape Carrier

InsulKrimp Ring [190700154](#)

Tongue Terminal for
10-12 AWG Wire,
Stud Size 3/8" (M9),
Length 34.21mm,
Mylar Tape Carrier

InsulKrimp Ring [190700156](#)

Tongue Terminal for
10-12 AWG Wire,

Stud Size 5/16" (M8),
Length 34.21mm,
Mylar Tape Carrier
Avikrimp Ring 190730162
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 6 (M3.5),
Length 27.71mm,
Mylar Tape Carrier
Avikrimp Ring 190730164
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 6 (M3.5),
Expanded Flare,
Length 27.71mm,
Mylar Tape Carrier
Avikrimp Ring 190730167
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 8 (M4),
Length 27.71mm,
Mylar Tape Carrier
Avikrimp Ring 190730169
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 8 (M4),
Expanded Flare,
Length 27.71mm,
Mylar Tape Carrier
Avikrimp Ring 190730172
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 10 (M5),
Length 27.71mm,
Mylar Tape Carrier
Avikrimp Ring 190730174
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 10 (M5),
Expanded Flare,
Length 27.71mm,
Mylar Tape Carrier
Avikrimp Ring 190730180
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 10 (M5),
Length 31.95mm,
Mylar Tape Carrier
Avikrimp Ring 190730184
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 10 (M5),
Expanded Flare,
Length 31.95mm,
Mylar Tape Carrier
Avikrimp Ring 190730190
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 1/4" (M6),
Length 31.95mm,
Mylar Tape Carrier
Avikrimp Ring 190730194
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 1/4" (M6),

Expanded Flare,
Length 31.95mm,
Mylar Tape Carrier
Avikrimp Ring 190730201
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 5/16" (M8),
Length 31.95mm,
Mylar Tape Carrier
Avikrimp Ring 190730205
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 5/16" (M8),
Expanded Flare,
Length 31.95mm,
Mylar Tape Carrier
Avikrimp Ring 190730218
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 6 (M3.5),
Length 26.59mm,
Mylar Tape Carrier
Avikrimp Ring 190730224
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 8 (M4),
Length 26.59mm,
Mylar Tape Carrier
Avikrimp Ring 190730226
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 8 (M4),
Expanded Flare,
Length 26.59mm,
Mylar Tape Carrier
Avikrimp Ring 190730232
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 1/4" (M6),
Length 34.59mm,
Mylar Tape Carrier
Avikrimp Ring 190730234
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 1/4" (M6),
Expanded Flare,
Length 34.59mm,
Mylar Tape Carrier
Avikrimp Ring 190730237
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 3/8" (M9),
Length 34.59mm,
Mylar Tape Carrier
Avikrimp Ring 190730239
Tongue Terminal for
10 to 12 AWG Wire,
Stud Size 3/8" (M9),
Expanded Flare,
Length 34.59mm,
Mylar Tape Carrier
InsulKrimp Ring 190800006
Tongue Terminal for
10-12 AWG Heavy

Duty Wire, Stud Size
6, 8, 10

MULTI-STUD 190810006

AVIKRIMP TAPED
(C-5006-MST)

InsulKrimp Snap 190990049
Spade Terminal for
10-12 AWG Wire,
Yellow

InsulKrimp Snap 190990051
Spade for 10-12
AWG Wire, Stud
Size 10 (M5), Mylar
Tape Carrier, Yellow

InsulKrimp Flanged 191210048
Spade Tongue
Terminal for 10-12
AWG Wire, Stud
Size 8 (M4), Width
8.13mm, Mylar Tape
Carrier

InsulKrimp Flanged 191210054
Spade Tongue
Terminal for 10-12
AWG Wire, Stud
Size 8 (M4), Width
9.53mm, Mylar Tape
Carrier

InsulKrimp Flanged 191210057
Spade Tongue
Terminal for 10-12
AWG Wire, Stud
Size 10 (M5), Width
9.53mm, Mylar Tape
Carrier

Avikrimp Flanged 191270087
Spade Tongue
Terminal for 10-12
AWG Wire, Stud
Size 8 (M4), Mylar
Tape Carrier

Avikrimp Flanged 191270090
Spade Tongue
Terminal for 10-12
AWG Wire, Stud
Size 10 (M5), Mylar
Tape Carrier

InsulKrimp Spade 191440041
Tongue Terminal for
10-12 AWG Wire,
Tape and Reel

InsulKrimp Spade 191440043
Tongue Terminal for
10-12 AWG Wire,
Tape and Reel

InsulKrimp Butt 191540030
Splice for 10-12
AWG Wire, Tape and
Reel

Avikrimp Hook 191830020
Tongue Terminal for
10-12 AWG Wire,
Stud Size 10 (M5),
Mylar Tape Carrier

Avikrimp Block Spade Terminal for 10-12 AWG Wire	<u>191980040</u>
Avikrimp Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier	<u>191980048</u>
Avikrimp Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier	<u>191980051</u>
Avikrimp Wire Pin Terminal for 12-10 AWG Wire, Mylar Tape Carrier	<u>192130008</u>

This document was generated on 07/29/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63885-1500](#)