

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0639005200**
Status: **Active**
Overview: Application Tooling
Description: FineAdjust Applicator for 2.00mm Pitch Wire-to-Board Crimp Terminals, 24-30 AWG Wire, Insulation OD 1.10-1.30mm

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Application Tooling
Series	<u>207127</u>
Comments	See Tooling Specification (PDF) Above
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	<u>Application Tooling</u>
Product Name	FineAdjust
Tool Type	Applicator
UPC	883906020507
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Physical


Net Weight 4977.361/g

Material Info

Reference - Drawing Numbers

Application Tooling Documents

ATS-639005200-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001, TM-638004900-001, TM-638004900CN-001, TM-638004900SP-001

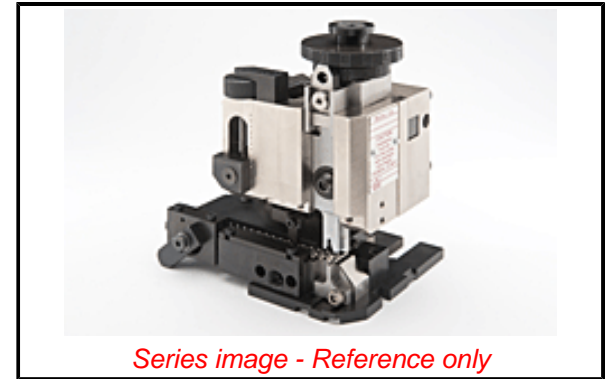

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

207127 Series

Use With

Molex TM-3000: [638017200](#) , [638017300](#) , Molex TM-4000: [638017600](#) , Molex TM-2000: [638008300](#) , [638008400](#) , and Most Industry Standard Presses or Wire Process Machines

Application Tooling

Description

FAQ

Product #

2.00mm Pitch, Micro-Latch Female Crimp Terminal, Tin (Sn) Plating, 24-30 AWG, Reel	502128000
2.00mm Pitch, Milli-Grid Female Crimp Terminal, 0.38µm Select Gold, Reel, Lead free	503948051
2.00mm Pitch, Milli-Grid Female Crimp Terminal, 0.76µm Select Gold, Reel, Lead-Free	503948052

2.00mm Pitch, Milli- Grid Female Crimp Terminal, Gold (Au) Flash, Reel, Lead free	<u>503948054</u>
2.00mm Pitch, Milli- Grid Female Crimp Terminal, Matte Tin Plating, Reel, Lead free	<u>503948055</u>
2.00mm Pitch, Milli- Grid Female Crimp Terminal, Unplated, Reel, Lead-Free	<u>503948999</u>
Micro-Latch 2.0 Rec Term Gold 0.1 #24-28	<u>593548081</u>

This document was generated on 07/30/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63900-5200](#)